


IEC PTFE insulated Twin Twisted Exposed Junction Thermocouple with Miniature Plug/Bare Tails - Types K, J, T

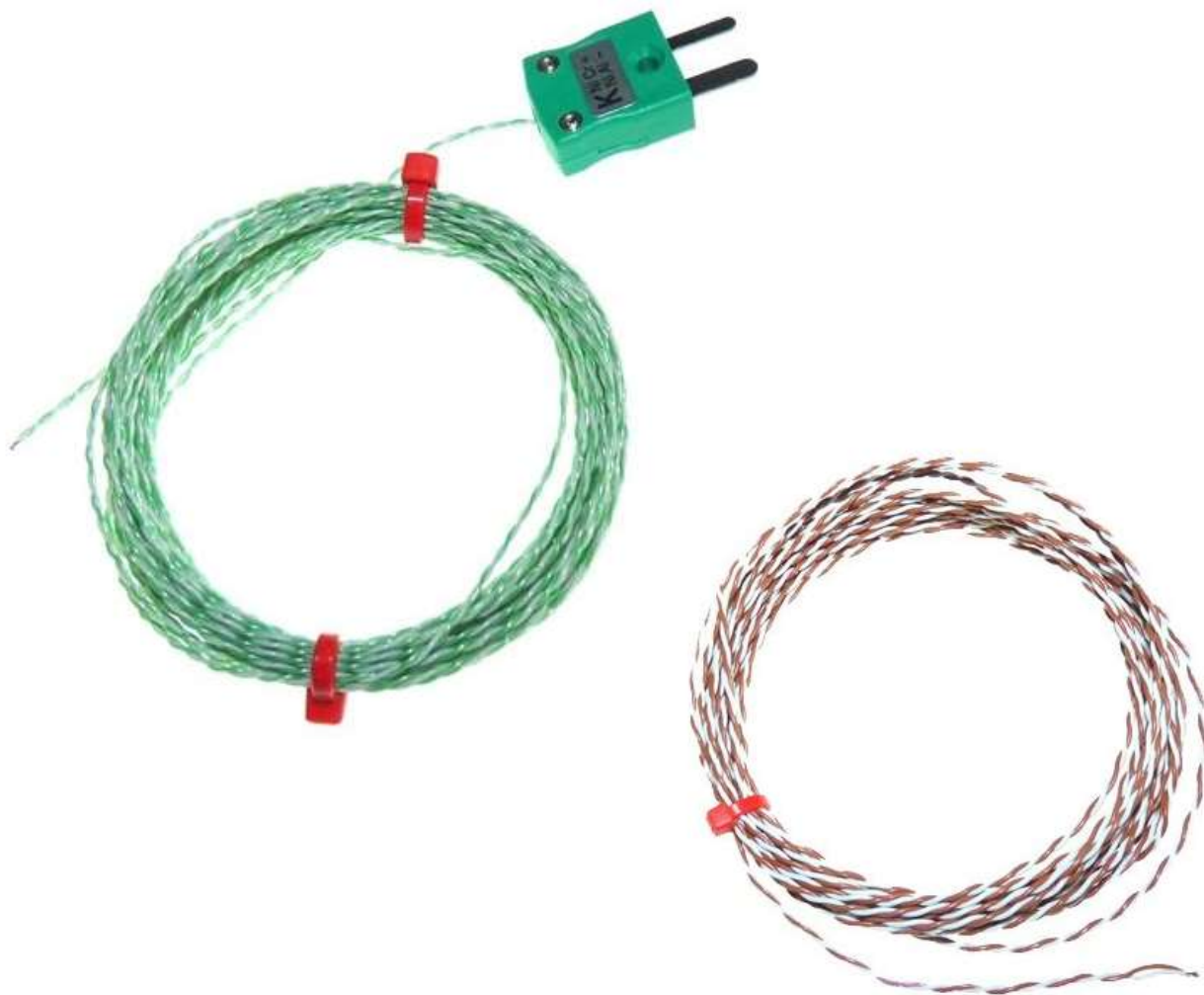

Labfacility are the UK's leading manufacturer of Temperature Sensors, Thermocouple Connectors and associated Temperature Instrumentation and stockists of Thermocouple Cables. The Company has been trading since 1971 and is ISO 9001 accredited.

Labfacility have supplied Farnell for over 30 years, and an extensive range of our products are available to buy online, from stock, direct from Farnell.

Specifications

General Description	Fast response, welded exposed junction
Thermocouple Type	K, J & T
Cable Length	0.25, 0.3, 1, 2, 3, 5 & 10m
Cable Type	Teflon® PTFE insulated twin-twisted lead
Core / Strands	1/0.2mm
Termination Type	Miniature flat pin plug colour coded in accordance IEC 584 or bare tails
Max. Temperature	+260°C
Min. Temperature	-75°C
Tolerance	Class 1
Standards Met	IEC-584-3

Ordering Information

Type	Style	Material	Cable Size	Length	Termination	Manufacturers Code	Farnell Number
K	Twisted	PTFE	1/0.2mm	250mm (0.82ft)	Bare Tails	Z2-K-1/0.2mm-250mm-T	XF-3031-FAR
K	Twisted	PTFE	1/0.2mm	0.3m (0.98ft)	Bare Tails	Z2-K-1/0.2mm-0.3-T	XF-3032-FAR
K	Twisted	PTFE	1/0.2mm	1m (3.3ft)	Bare Tails	Z2-K-1/0.2mm-1m-T	7076150
K	Twisted	PTFE	1/0.2mm	2m (6.56ft)	Bare Tails	Z2-K-1/0.2mm-2m-T	7076162
K	Twisted	PTFE	1/0.2mm	3m (9.84ft)	Bare Tails	Z2-K-1/0.2mm-3m-T	1633481
K	Twisted	PTFE	1/0.2mm	5m (16.4 ft)	Bare Tails	Z2-K-1/0.2mm-5m-T	1633482

Type	Style	Material	Cable Size	Length	Termination	Manufacturers Code	Farnell Number
T	Twisted	PTFE	1/0.2mm	0.3m (0.98ft)	Bare Tails	Z2-T-1/0.2mm-0.3-T	XF-3033-FAR
T	Twisted	PTFE	1/0.2mm	1m (3.3ft)	Bare Tails	Z2-T-1/0.2mm-1m-T	7076174
T	Twisted	PTFE	1/0.2mm	2m (6.56ft)	Bare Tails	Z2-T-1/0.2mm-2m-T	7076186
T	Twisted	PTFE	1/0.2mm	3m (9.84ft)	Bare Tails	Z2-T-1/0.2mm-3m-T	1633483
T	Twisted	PTFE	1/0.2mm	5m (16.4 ft)	Bare Tails	Z2-T-1/0.2mm-5m-T	1633484

Type	Style	Material	Cable Size	Length	Termination	Manufacturers Code	Farnell Number
J	Twisted	PTFE	1/0.2mm	0.3m (0.98ft)	Miniature Plug	Z2-J-1/0.2mm-0.3-MP	XF-3037-FAR
J	Twisted	PTFE	1/0.2mm	1m (3.3ft)	Miniature Plug	Z2-J-1/0.2mm-1m-MP	2785061
J	Twisted	PTFE	1/0.2mm	2m (6.56ft)	Miniature Plug	Z2-J-1/0.2mm-2m-MP	2785065
J	Twisted	PTFE	1/0.2mm	3m (9.84ft)	Miniature Plug	Z2-J-1/0.2mm-3m-MP	4073375
J	Twisted	PTFE	1/0.2mm	5m (16.4 ft)	Miniature Plug	Z2-J-1/0.2mm-5m-MP	2785066
J	Twisted	PTFE	1/0.2mm	10m (32.8ft)	Miniature Plug	Z2-J-1/0.2mm-10m-MP	2785067

Type	Style	Material	Cable Size	Length	Termination	Manufacturers Code	Farnell Number
K	Twisted	PTFE	1/0.2mm	0.3m (0.98ft)	Miniature Plug	Z2-K-1/0.2mm-0.3-MP	XF-3059-FAR
K	Twisted	PTFE	1/0.2mm	1m (3.3ft)	Miniature Plug	Z2-K-1/0.2mm-1m-MP	4100748
K	Twisted	PTFE	1/0.2mm	2m (6.56ft)	Miniature Plug	Z2-K-1/0.2mm-2m-MP	2785062
K	Twisted	PTFE	1/0.2mm	3m (9.84ft)	Miniature Plug	Z2-K-1/0.2mm-3m-MP	4073367
K	Twisted	PTFE	1/0.2mm	5m (16.4 ft)	Miniature Plug	Z2-K-1/0.2mm-5m-MP	2785063
K	Twisted	PTFE	1/0.2mm	10m (32.8ft)	Miniature Plug	Z2-K-1/0.2mm-10m-MP	2785064
Type	Style	Material	Cable Size	Length	Termination	Manufacturers Code	Farnell Number
T	Twisted	PTFE	1/0.2mm	0.3m (0.98ft)	Miniature Plug	Z2-T-1/0.2mm-0.3-MP	XF-3060-FAR
T	Twisted	PTFE	1/0.2mm	1m (3.3ft)	Miniature Plug	Z2-T-1/0.2mm-1m-MP	4100750
T	Twisted	PTFE	1/0.2mm	2m (6.56ft)	Miniature Plug	Z2-T-1/0.2mm-2m-MP	2785068
T	Twisted	PTFE	1/0.2mm	3m (9.84ft)	Miniature Plug	Z2-T-1/0.2mm-3m-MP	4073355
T	Twisted	PTFE	1/0.2mm	5m (16.4 ft)	Miniature Plug	Z2-T-1/0.2mm-5m-MP	2785069
T	Twisted	PTFE	1/0.2mm	10m (32.8ft)	Miniature Plug	Z2-T-1/0.2mm-10m-MP	3584271