

Category 6 Low Profile Patch Leads



Category 6 Low Profile Patch Leads (SP*)

* = Length

? = Colour

Features

- High performance patch cord compliant with the Category 6 standard at patch cord/component level (TIA/EIA-568-B.2-1)
- Low profile cordage (only 4.15mm OD) enables high density patching and excellent flexibility
- Fitted with flush moulded snag-less strain relief boots, suitable for patching into high density hubs and switches
- Individually polythene bagged and marked with length
- Colours: grey, red, yellow, green, black and blue. Additional colours available to order
- 100% tested

Specifications

Materials

- Contacts: 50µ"/1.27µm gold plated
- Conductors: 26 AWG stranded pure copper
- Jacket: PVC

Lengths (m): 0.5, 1, 2, 3, 5, 10

Colours: blue (bl), black (bk), green (gn), grey (gy), red (rd), yellow (yw)

Packaging: Packed in individual poly bags, then in 20s


Commodity code: 85444920

EAN: Available on request

Country of Origin: China

ROHS Compliant


Code: SP*?
 *=Colour
 ?=Length

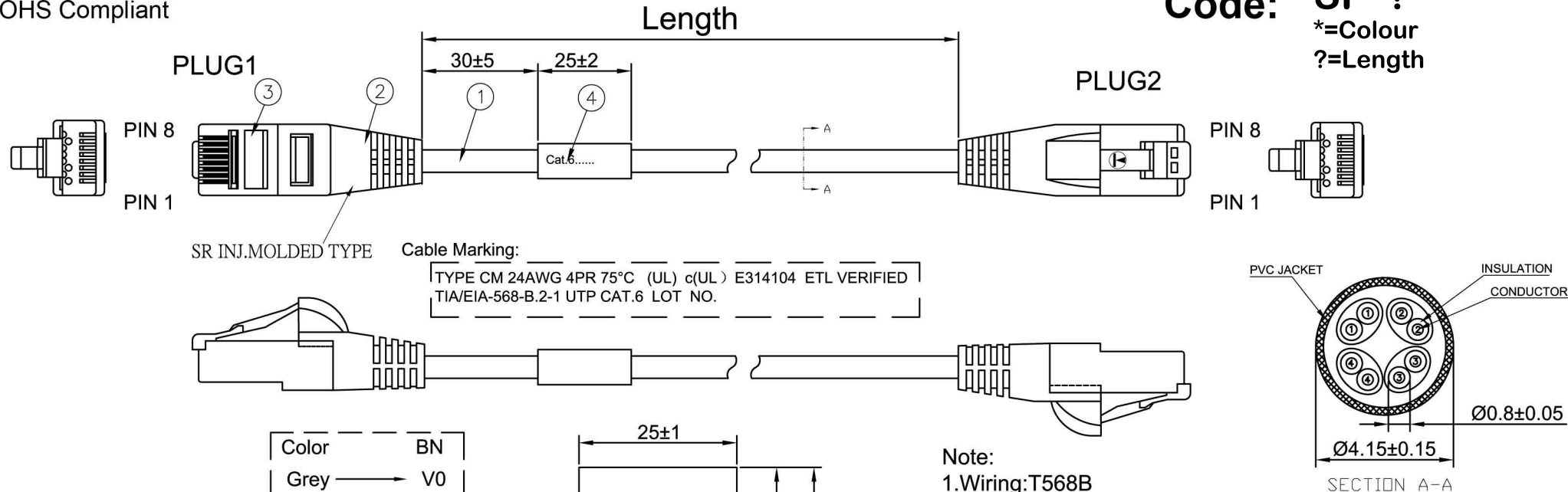

Color	BN
Grey	V0
Red	W5
Blue	CG

WIRING: T568B

PLUG1	PLUG2	COLOR
PIN1	PIN1	WHITE/ORANGE
PIN2	PIN2	ORANGE
PIN3	PIN3	WHITE/GREEN
PIN4	PIN4	BLUE
PIN5	PIN5	WHITE/BLUE
PIN6	PIN6	GREEN
PIN7	PIN7	WHITE/BROWN
PIN8	PIN8	BROWN

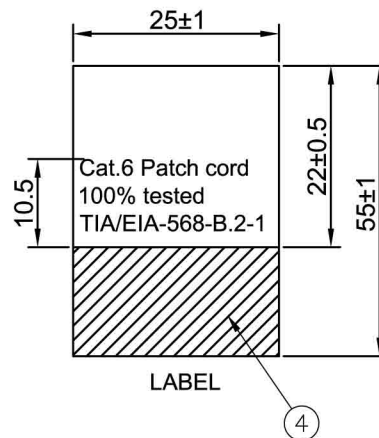

LENGTH=0.5M,1M,2M,3M,5M,10M

Note:
 1.Wiring:T568B
 2.Tolerance:
 Length≤1M,Tolerance+50/-0mm
 Length>1M&≤5M,Tolerance±50mm
 Length>5M,Tolerance±100mm

④	Label	PAPER	WHITE BACKED 22x55mm	1
				2
③	PLUG	PC V0	8P8C 50U" Gold Plated	2
				2
②	MOLDING	PVC	80Pa	2
①	Cable	PVC	UTP CAT.6 26AWG(7*0.16)	1
NO.	Name	Material	Specification	Q'ty