


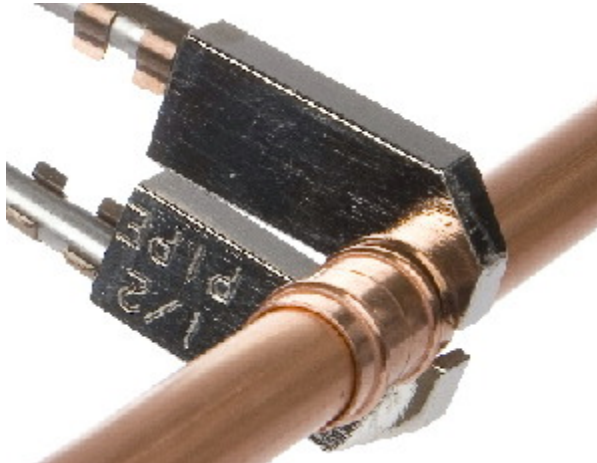

Replacement Heads for Pipemaster



**PIPEMASTER**

Specification	Details
Voltage	220/240V AC
Power	120W (600W Inrush)
Warm up time (from cold)	Approx. 4 minutes
Head temperature	520° C
Usage time* 15mm	1st joint 20-30 secs 2nd joint 10 secs
Usage time* 22 mm	1st joint 30-40 secs 2nd joint 10 secs
Head sizes available	8,10,14,15,16,18,22 3/8", 1/2", 3/4" ID (for USA)
Fitted heads	15mm
Construction	Polycarbonate moulded parts Stainless steel element shafts Nickel plated copper heads
Lead wire	3 core cable 1.8m
Plug	Moulded plug available as an option
Stand	Included, flat packed

\*Times can vary depending on condition of pipe, fittings, ambient temperature, etc..