



Part Number : [1300940507](#)


Product Description : Bus-Drop Support Grip,
Single Eye, Cable Diameter 17.78-24.64mm
(.700-.970"), Approximate Break Strength
462.66kg (1020 lbs)

Series Number : 130094

Status : Active

Product Category : Cable Grips

Engineering Number : 36578

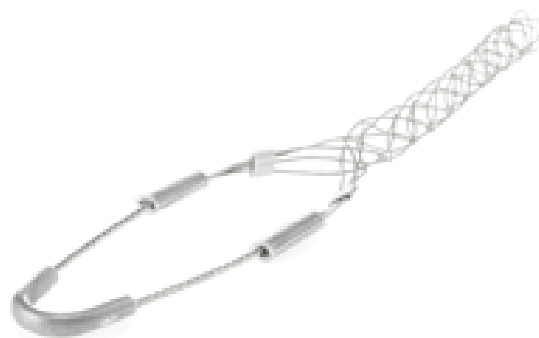

Documents & Resources

Drawings

[PK-130227-004-001.pdf](#)

Product Environment Compliance

Compliance

China RoHS	Not Reviewed
EU ELV	Not Reviewed
Low-Halogen Status	Not Reviewed
REACH SVHC	Not Reviewed
EU RoHS	Not Reviewed

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Cable Grips
Series	130094
Description	Bus-Drop Support Grip, Single Eye, Cable Diameter 17.78-24.64mm (.700-.970"), Approximate Break Strength 462.66kg (1020 lbs)
Product Name	Service-Drop
Type	Support Grip
UPC	78678835821

Agency

CSA	LR32159
-----	---------

Physical

Approximate Break Strength	462.66kg (1020 lbs)
Bale Length	0.203m (8.00")
Body Style	Straight
Cable Diameter	17.78-24.64mm (.700-.970")
Color - Grommet	N/A
Eye Type	Single
Gender	N/A
Material - Body	N/A
Material - Grip	Galvanized Steel
Mesh Length	0.229m (9.00")
Number of Holes	N/A
O-Ring	N/A
Thread Size	N/A