



Connectors > Power Connectors > Circular Power > Circular Power Connectors



Number of Positions: 4

Connector Product Type: **Housing**

Operating Voltage: **600 VDC**

Connector System: **Wire-to-Wire**

Sealable: **No**

Features

Product Type Features

|                                   |              |
|-----------------------------------|--------------|
| Connector Product Type            | Housing      |
| Connector System                  | Wire-to-Wire |
| Sealable                          | No           |
| Connector & Contact Terminates To | Wire & Cable |
| Connector & Housing Type          | Receptacle   |
| Circular Connector Shell Type     | All Plastic  |

Configuration Features

|                            |         |
|----------------------------|---------|
| Reverse Numbering          | Without |
| Number of Positions        | 4       |
| Number of Power Positions  | 0       |
| Number of Signal Positions | 4       |

Electrical Characteristics

|                   |         |
|-------------------|---------|
| Operating Voltage | 600 VAC |
|-------------------|---------|

Contact Features



|                    |        |
|--------------------|--------|
| Reverse Gender     | Yes    |
| Contact Type       | Socket |
| Contact Protection | With   |

Mechanical Attachment

|                          |                            |
|--------------------------|----------------------------|
| Mating Retention Type    | Threaded Coupling          |
| Thread Size              | 5/8-24 UNEF-2A             |
| Polarization Code        | A                          |
| Panel Mount Feature Type | Flange with Mounting Holes |
| Mating Alignment Type    | Keyed                      |
| Mating Alignment         | With                       |
| Connector Mounting Type  | Panel Mount                |
| Mating Retention         | With                       |
| Panel Mount Feature      | With                       |

Housing Features

|                               |          |
|-------------------------------|----------|
| Body Orientation              | Straight |
| Housing Color                 | Black    |
| Housing Material              | Nylon    |
| Circular Connector Shell Size | 11       |

Usage Conditions

|                             |                            |
|-----------------------------|----------------------------|
| Operating Temperature Range | -55 – 105 °C[-67 – 221 °F] |
| Fluid Resistance            | None                       |

Operation/Application

|                     |                |
|---------------------|----------------|
| Circuit Application | Power & Signal |
| Shielded            | No             |

Industry Standards

|                        |          |
|------------------------|----------|
| UL Flammability Rating | UL 94V-0 |
|------------------------|----------|

Packaging Features

|                    |         |
|--------------------|---------|
| Packaging Quantity | 1       |
| Packaging Method   | Package |

Product Compliance

For compliance documentation, visit the product page on TE.com>



|                                               |                                                                                                                                 |
|-----------------------------------------------|---------------------------------------------------------------------------------------------------------------------------------|
| EU RoHS Directive 2011/65/EU                  | Compliant                                                                                                                       |
| EU ELV Directive 2000/53/EC                   | Compliant                                                                                                                       |
| China RoHS 2 Directive MIIT Order No 32, 2016 | No Restricted Materials Above Threshold                                                                                         |
| EU REACH Regulation (EC) No. 1907/2006        | Current ECHA Candidate List: JUNE 2024 (241)<br>Candidate List Declared Against: JUNE 2024 (241)<br>Does not contain REACH SVHC |
| Halogen Content                               | BFR/CFR/PVC Free, but Br/Cl >900 ppm in other sources.                                                                          |
| Solder Process Capability                     | Not applicable for solder process capability                                                                                    |

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 2386906-2  
LUG CONN CA,REV,SER 1,SZ 11-4,  
LGTH 1.0 M




TE Part # 206358-5  
CABLE CLAMP ASY, SIZE 11



TE Part # 1-2407269-2  
CAP, CPC, SIZE 11 RECP & 13 PLUG,  
BLACK



TE Part # 2386906-1  
LUG CONN CA,REV,SER 1,SZ 11-4,  
LGTH 0.5 M

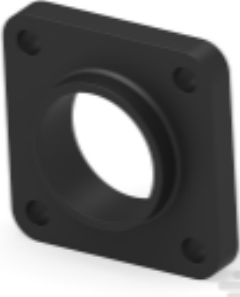

TE Part # 207299-1  
PLUG MTG. FLANGE NO 11 CPC



TE Part # 1-206062-7  
CABLE CLAMP KIT, BULK PKG




TE Part # 1-2407269-3  
CAP, CPC, SIZE 11 RECP & 13 PLUG,  
RED



TE Part # 2386906-3  
LUG CONN CA,REV,SER 1,SZ 11-4,  
LGTH 2.0 M



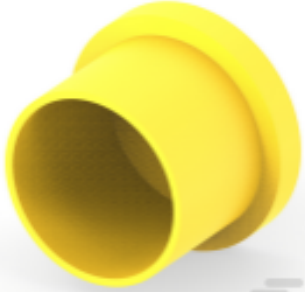

|                                                                                                                                         |                                                                                                                                               |                                                                                                                                                                   |                                                                                                                                                                   |
|-----------------------------------------------------------------------------------------------------------------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------------------------------------------------------------------------------------|
|  <p>TE Part # 207490-1<br/>CABLE GRIPPER, SIZE 11</p>  |  <p>TE Part # 796379-2<br/>R/A STRN RELIEF KIT,SZ 11,CPC</p> |  <p>TE Part # 1546347-2<br/>R/A CABLE CLAMP KIT,SZ 11,CPC</p>                  |  <p>TE Part # 206429-1<br/>CPC PLUG ASSY, 11-4, REV SEX</p>                    |
|  <p>TE Part # 213811-1<br/>COUPLING RING,SZ 11,CPC</p> |  <p>TE Part # 207489-1<br/>FLEXIBLE CABLE BOOT, SIZE 11</p>  |  <p>TE Part # 1-2407269-4<br/>CAP, CPC, SIZE 11 RECP &amp; 13 PLUG, YELLOW</p> |  <p>TE Part # 1-2407269-1<br/>CAP, CPC, SIZE 11 RECP &amp; 13 PLUG, ORANGE</p> |
|  <p>TE Part # 1-206062-4<br/>CABLE CLAMP KIT #11</p> |  <p>TE Part # 206358-6<br/>CABLE CLAMP KIT, BULK PKG</p>   |                                                                                                                                                                   |                                                                                                                                                                   |

Also in the Series | AMP CPC

|                                                                                                                                          |                                                                                                                           |                                                                                                                      |                                                                                                                     |
|------------------------------------------------------------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------------------------------------------|----------------------------------------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------------------------------------|
|  <p>Circular Connector Backshells &amp; Clamps(1)</p> |  <p>Circular Power Connectors(211)</p> |  <p>Connector Contacts(260)</p> |  <p>Connector Hardware(12)</p> |
|  <p>Power Contacts(260)</p>                           |  <p>Sealing Sleeves(2)</p>             |                                                                                                                      |                                                                                                                     |

Also in the Series | CPC Series 1





Circular Power Connectors(211)



Connector Contacts(260)




Power Contacts(260)

Customers Also Bought



TE Part #206060-1  
CPC PLUG ASSEMBLY SIZE 11-4

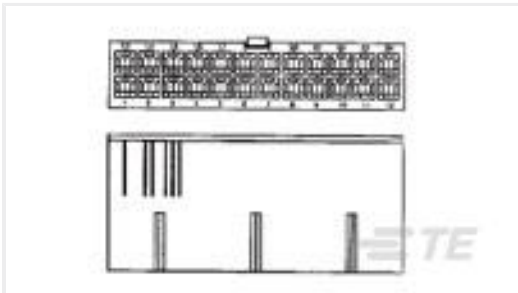

TE Part #2-1586017-4  
24P FH PLUG VAL-U-LOK V0



TE Part #1-206062-6  
CABLE CLAMP KIT #11



TE Part #206966-7  
CABLE SHELL CLAMP SIZE 13



TE Part #206070-8  
CABLE CLAMP KIT #17



TE Part #206061-1  
RECPT, SZ 11-4, CPC



TE Part #206429-1  
CPC PLUG ASSY, 11-4, REV SEX



TE Part #206708-1  
CPC PLUG ASSEMBLY SIZE 13-9



TE Part #211768-1  
CPC PLUG ASSEMBLY SIZE 17-9



TE Part #1-206062-4  
CABLE CLAMP KIT #11

Documents

Product Drawings  
RECPT, SZ 11-4, CPC  
English

CAD Files  
3D PDF  
3D  
Customer View Model  
ENG\_CVM\_CVM\_206430-1\_AC.2d\_dxf.zip



English

Customer View Model

[ENG\\_CVM\\_CVM\\_206430-1\\_AC.3d\\_igs.zip](#)

English

Customer View Model

[ENG\\_CVM\\_CVM\\_206430-1\\_AC.3d\\_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[AMP Circular Connectors for Commercial Signal & Power Applications](#)

English

Product Specifications

[Application Specification](#)

English

Instruction Sheets

[Instruction Sheet \(U.S.\)](#)

English

Agency Approvals

[UL Report](#)

English