


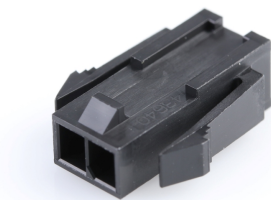

**Part Number :** [436400208](#)  
**Product Description :** Micro-Fit 3.0 Plug Housing, Single Row, 2 Circuits, UL 94V-0, Panel Mount Ears, Low-Halogen Since Inception, Black  
**Series Number :** 43640  
**Status :** Active  
**Product Category :** Connector Housings



## Documents & Resources


**Drawings**  
[436400208\\_sd.pdf](#)

**3D Models and Design Files**  
[436400208\\_stp.zip](#)

**Specifications**  
[PK-43640-003-001.pdf](#)  
[436500001-PS-JA-000.pdf](#)  
[436500001-PS-KO-000.pdf](#)  
[436500001-PS-SP-000.pdf](#)  
[PS-43650-001.pdf](#)  
[430450005-TS-000.pdf](#)  
[430450007-TS-000.pdf](#)  
[TS-43045-001-001.pdf](#)  
[TS-43045-002-001.pdf](#)  
[TS-43045-003-001.pdf](#)  
[TS-46235-001-001.pdf](#)

## Product Environment Compliance

### Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Compliant per EU 2015/863

## Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

## Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

## EU RoHS Certificate of Compliance

---

### Part Details

#### General

Status	Active
Category	Connector Housings
Series	43640
Description	Micro-Fit 3.0 Plug Housing, Single Row, 2 Circuits, UL 94V-0, Panel Mount Ears, Low-Halogen Since Inception, Black
Application	Power, Wire-to-Wire
Comments	Halogen Free/Low Halogen since inception
Product Name	Micro-Fit 3.0
UPC	883906114350

#### Agency

CSA	LR19980
UL	E29179

#### Physical

Circuits (maximum)	2
Color - Resin	Black
Flammability	94V-0
Gender	Plug
Glow-Wire Capable	No

Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	0.391/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	Yes
Pitch - Mating Interface	3.00mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C

## Solder Process Data

Lead-Free Process Capability	N/A
------------------------------	-----

---

## Mates With / Use With

### Mates with Part(s)

Description	Part Number
Micro-Fit 3.0 Single Row Receptacle Housings	<u>43645</u>
Micro-Fit TPA-to-Micro-Fit TPA Off-the-Shelf (OTS) Cable Assemblies	<u>145132</u>
Micro-Fit 3.0 Female-to-Micro-Fit 3.0 Female Off-the-Shelf (OTS) Cable Assemblies	<u>214750</u>
Micro-Fit 3.0 Female-to-Pigtail Off-the-Shelf (OTS) Cable Assemblies	<u>214751</u>

### Use with Part(s)

Description	Part Number
Micro-Fit Male Crimp Terminals	<u>43031</u>
Pre-Crimped Lead Micro-Fit 3.0 Male-to-Micro-Fit 3.0 Male	<u>214762</u>
Pre-Crimped Lead Micro-Fit 3.0 Male-to-Pigtail	<u>214763</u>

---

