




Connectors > Connector Accessories > Connector Caps & Covers

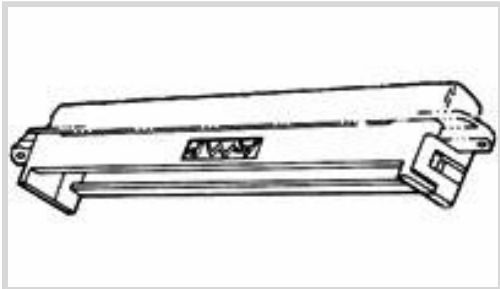

Connector Cover Type: **Strain Relief Cover**

Features

Product Type Features

Connector Cover Type	Strain Relief Cover
----------------------	---------------------

Dimensions

	1.455 in
--	----------

Packaging Features

Packaging Method	Package
Packaging Quantity	1

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Bromine/Chlorine - Br and Cl < 900 ppm per homogenous material. Also BFR /CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer


This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these




limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Also in the Series


CHAMP Docking Connectors




Connector Caps & Covers(28)




Connector Hardware(28)



Connector Strain Relief(2)



Docking Connectors(19)

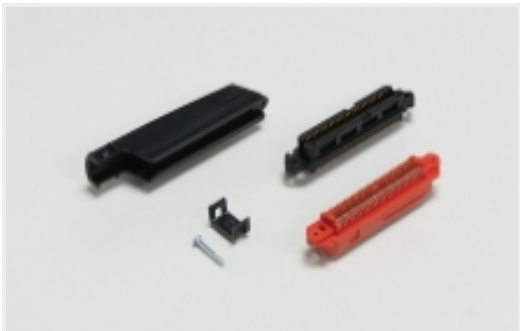

IDC D-Sub Connectors(55)

Customers Also Bought



TE Part #YDTS20F11-05ANV001
RECP ASSY



TE Part #2213765-7
AV19 SPM 3A SPOT LED RED 24V



TE Part #T1280242132-000
H24B-TGBH-M32



TE Part #1-104656-0
100 50/50 HDR DRST SFMNT .320



TE Part #102102-5
MOD I RECP STMPD



TE Part #87608-1
10 MODII HDR DRST SHRD .100CL



TE Part #5552126-1
ASSY, PLUG, 50 POS, EDGE MTG



TE Part #DTS26F21-35SN-6149
PLUG ASSY



Documents

Product Drawings

STRAIN RELIEF 24 POS BLACK

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_1-552298-1_M.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_1-552298-1_M.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_1-552298-1_M.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Instruction Sheets

Instruction Sheet (U.S.)

English