


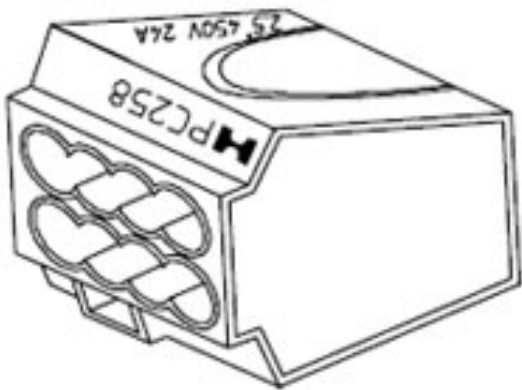

Part Number : [194300001](#)
Product Description : See and Splice 2 Circuit
Push-in Wire Connector for 22-12 AWG Wire
Series Number : 19430
Status : Active
Product Category : Splices
Engineering Number : PC2-RED




Documents & Resources

Drawings
[194300001_sd.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per ED/88/2018 (15 January 2019)
EU RoHS	Compliant per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Part Details

General

Status	Active
Category	Splices
Series	19430
Description	See and Splice 2 Circuit Push-in Wire Connector for 22-12 AWG Wire
Comments	Red Insert, 1000V max. for lighting/sign fixtures
Product Name	See and Splice
UPC	822348218882

Agency

UL	E32244
----	--------

Electrical

Voltage - Maximum	600V
-------------------	------

Physical

Barrel Type	Closed
Color - Resin	Red
Flammability	94V-2
Insulation	None
Material - Metal	Brass
Material - Plating Mating	N/A
Net Weight	1.736/g
Packaging Type	Bag
Temperature Range - Operating	-30° to +105°C
Wire Insulation Diameter	3.30mm is the nominal O.D.
Wire Size (AWG)	12, 14, 16, 18, 20, 22