




Connectors > Automotive Connectors > Automotive Connector Accessories > Automotive Connector Caps & Covers

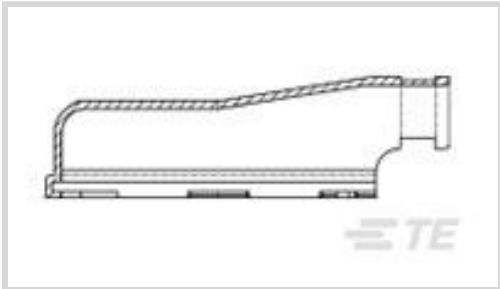

Primary Product Color: **Black**

Protection & Strain Relief Accessory Type: **Cover - Cable Exit**

Primary Product Material: **PBT**

Strain Relief: **With**

Features

Product Type Features

Protection & Strain Relief Accessory Type	Cover - Cable Exit
---	--------------------

Body Features

Primary Product Color	Black
Primary Product Material	PBT

Mechanical Attachment

Strain Relief	With
---------------	------

Dimensions

Compatible Cable Bundle Diameter Range	12.7 mm[.5 in]
--	----------------

Industry Standards

UL Flammability Rating	UL 94HB
------------------------	---------

Packaging Features

Packaging Method	Carton
------------------	--------

Other

Serviceable	Yes
-------------	-----

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant



China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

TE Part # CAT-T4827-CH8172
[Timer Connector Housing](#)

Also in the Series | Timer Connector System

Automotive Connector Caps & Covers (9)


Automotive Housings(285)

Automotive Terminals(153)

Crimp Terminal Housings(13)



Other Automotive Connector Accessories(2)

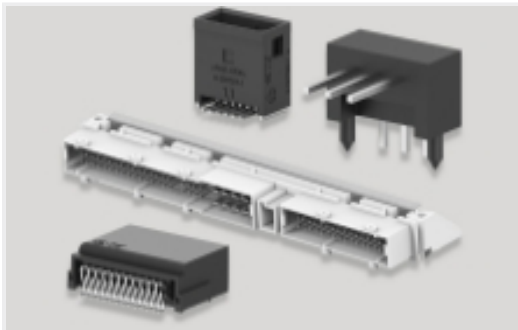

PCB Headers & Receptacles(19)



Quick Disconnects(4)




Rectangular Power Connectors(2)

Also in the Series | Junior Power Timer




Automotive Connector Caps & Covers (9)

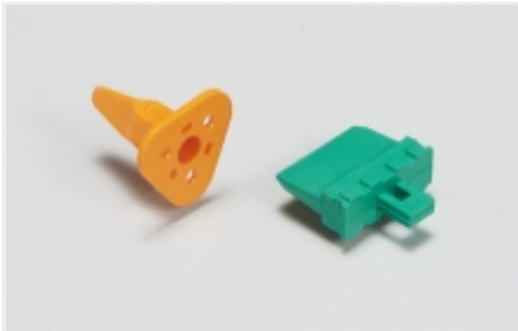

Automotive Connector Locks & Position Assurance(8)



Automotive Housings(285)

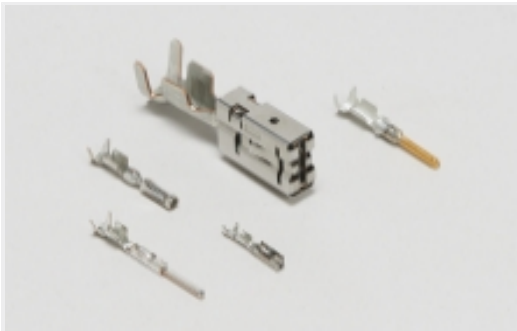

Automotive Terminals(153)




Busbars & Terminals(1)




Connector Seals & Cavity Plugs(7)



Insertion & Extraction Tools(8)

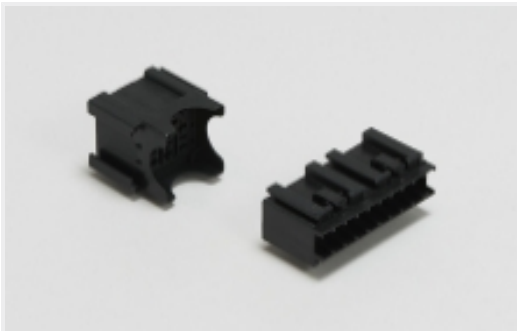

Module Components(1)

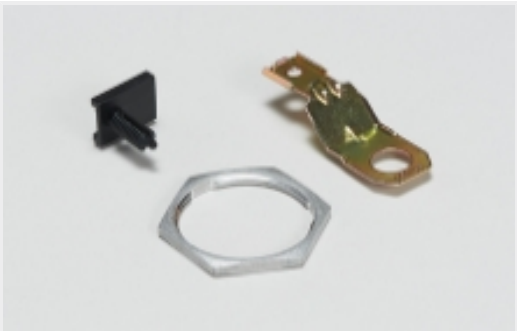

Other Automotive Connector Accessories(2)



Special Purpose Terminals(2)

Customers Also Bought





TE Part #9-1393211-3
T92S11D22-12



TE Part #DT04-2P-EE01
REC, 2P, BLK, N, XCAP



TE Part #0413-215-1605
SEALING PLUG, SIZE 16, KEYING, WHT



TE Part #HD36-24-91SN-059
PLG,9P,AL,N,CBLCCLMPBT,DRAIN,8/12/16,S,MC



TE Part #80052-000
LS309-31 Liquid Level Sensor



TE Part #CAT-T4827-CH8172
Timer Connector Housing



TE Part #66100-2
III+ SKT,18-16,TIN-LEAD,STRIP



TE Part #DRC26-50S02
PLG, 50P, BLK, N, 02

TE Part #955-181-016
CGNW 702659 SF S/FAKRAwp-na/D/C/E/5.0

Documents

Product Drawings
ABDECKKAPPE F42/29P

English

CAD Files
3D PDF

English

Customer View Model
ENG_CVM_962371-1_B1.2d_dxf.zip

English

Customer View Model
ENG_CVM_962371-1_B1.3d_igs.zip

English

Customer View Model
ENG_CVM_962371-1_B1.3d_stp.zip

English

By downloading the CAD file I accept and agree to the Terms and Conditions of use.

Instruction Sheets



Instruction Sheet (U.S.)

English