



Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts







TE Part # 1658620-9

40 NOVO MIL 15DP, LEAD FREE

Customers Also Bought





TE Part #5520425-3

MJ,TE,6P/6C,BULK PAC





TE Part #1614914-1


CPF0805 2K0 0.1% 25PPM 5K RL






TE Part #2003101-F

HDIM500GUY8P5; PRES; 0..500MBARD;SMD;5V

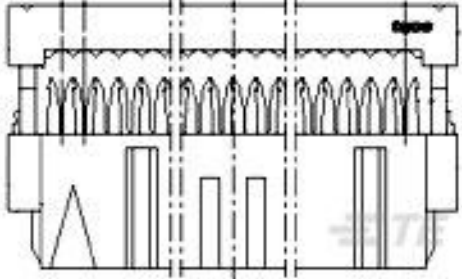



TE Part #3-215882-4


LATCH BU-STECK






TE Part #5-5179010-3

0.8FH,R13H.5,080,08/Sn,TU

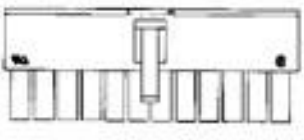



TE Part #1-794954-0

10P RCPT VAL-U-LOK V2





TE Part #292172-4

CT POST HDR ASSY 4P IN-TUBE BL





TE Part #180439-2

110 FASTON,REC.,20-16 AWG,TPBR





TE Part #6-2176369-0

RQ 0603 165R 0.1% 10PPM 5K RL

TE Part #AAF6406-00

100P2475-50-09-L50-CHP

Documents

Product Drawings

40P.A/L.STRAIN REL.

English

40P.A/L.STRAIN REL.

English

CAD Files

3D PDF

3D



Customer View Model

[ENG\\_CVM\\_CVM\\_4-100103-0\\_D.2d\\_dxf.zip](#)

English

Customer View Model

[ENG\\_CVM\\_CVM\\_4-100103-0\\_D.3d\\_igs.zip](#)

English

Customer View Model

[ENG\\_CVM\\_CVM\\_4-100103-0\\_D.3d\\_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.