


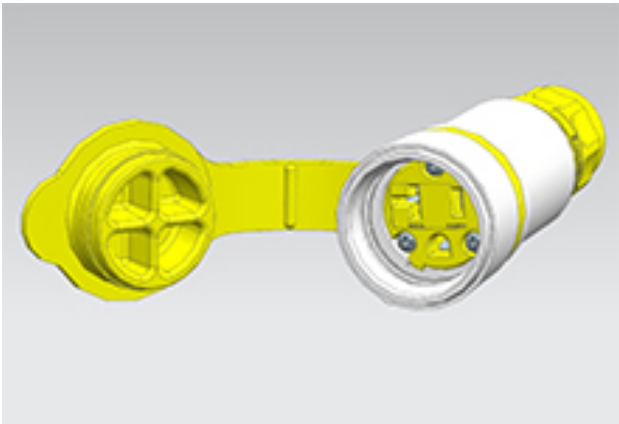

Part Number : [1301460054](#)
Product Description : Watertite Extreme
Ground Fault Monitoring Connector 2 Pole/3
Wire, NEMA 5-20, 125V, Cord Grip Body Size
F2, Silicone Husk
Series Number : 130146
Status : Active
Product Category : Wiring Devices
Engineering Number : 15W33GCM



Documents & Resources

Drawings
[1301460054_sd.pdf](#)

3D Models and Design Files
[1301460054_stp.zip](#)

Product Environment Compliance

Compliance

China RoHS	Not Reviewed
EU ELV	Not Reviewed
Low-Halogen Status	Not Reviewed
REACH SVHC	Not Reviewed
EU RoHS	Not Reviewed

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Part Details

General

Status	Active
Category	Wiring Devices
Series	130146
Description	Watertite Extreme Ground Fault Monitoring Connector 2 Pole/3 Wire, NEMA 5-20, 125V, Cord Grip Body Size F2, Silicone Husk
IP Rating	IP69K
NEMA Configuration	NEMA 5-20
Product Name	Watertite Extreme
Specialty	Monitoring
Type	Connector
UPC	78678805847

Agency

CSA	LR6837
UL	E10176

Electrical

Current - Maximum per Contact	20.0A
GFCI	No
Voltage - Maximum	125V

Physical

Cord Grip Body Size	F2 1/2"
Cord Type	N/A
Flange	No
Flip Lid	No
Gender	Female
Length	N/A
Lighted Connector	Yes
Locking Blade	No

Poles	2-pole/3-wire
Receptacle Type	Single

This document was generated on Mar 13, 2025