


Female To Female Standoff - Nylon ; Hexagonal ; M3 x 0.5 ; Spacer Length 4 mm | 0.157 in

This Nylon 6/6 Hexagonal M3 Female To Female Standoff is 4.0 mm |
0.157 in long

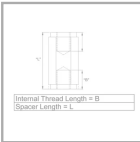

Useful Information

Documents

[Material Data Sheet](#)

Specifications

Distance Across Flats	0.217 in
Maximum Operating Temperature	185 °F
Minimum Operating Temperature	-40 °F
Operating Temperature Range	-40 - 185 °F
Spacer Length	0.157 in
Color	Natural
Thread Sizes (All)	M3 x 0.5
Full Material	Nylon 6/6
Material	Nylon



Material Flammability Standard	UL94 V-2
Spacer Shape	Hexagonal
Thread Standard	Metric
Thread Size	M3 x 0.5

Can't find what you're looking for? Tell us what you are looking for...

Send us your inquiry and we'll get back to you in 24 hours.

Contact us

Recently viewed items



**Grommet Sleeve -
Compatible Cable
Diameter 6.4 mm |
0.25...**

[See our selection →](#)




**Screw-On Feet - Base
Diameter - 9.7 mm |
0.380 in ; Base...**

[See our selection →](#)



**Screw-On Feet - Base
Diameter - 16 mm |
0.630 in ; Base ...**

[See our selection →](#)

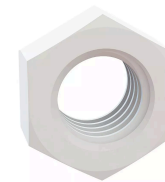

**Natural PA Standard Hex
Nut - Thread Size M3;
Distance ...**

[See our selection →](#)



**Female To Fem
Standoff - Nyl
Hexagonal ; M3**

[See our selection →](#)