 


Bottle Shapes, VG style

Art.-No. 401-54016 | 154-42-GW8-PO-X-BK | 




- Use in conjunction with circular grooved adaptors
- Strengthened strain relief by usage of an additional inner lip
- Excellent protection against environment impacts
- Eliminates moisture ingress to harness



More products in this product group:

[Bottle Shapes, VG style >](#)

Application	Heat shrinkable moulded shapes for use in Electrical and Electronic Cable Harness Applications.
Colour	Black (BK)
Material	Polyolefin, cross-linked (PO-X)
PART DESCRIPTION	154-42-GW8-PO-X-BK
Pack Content	1 pc.
Package Content packed in	pcs.
Product Family	Helashrink 150 Series, with rib
Product Group	Bottle Shapes, VG style
Shrink Ratio	up to 4.5:1
Type	154-42-GW8
Variant	For plug

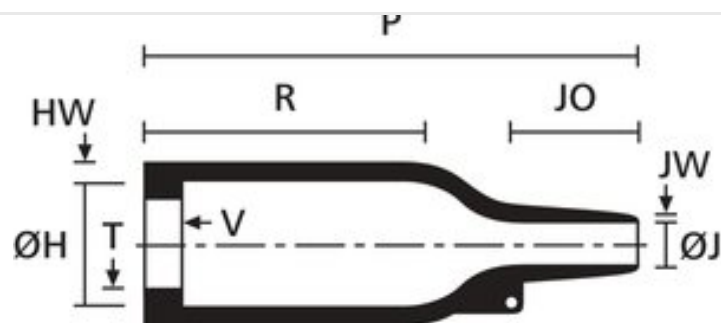

øH max. b	14 mm
øH min. a	30 mm
øJ max. b	6 mm
øJ min. a	30 mm
Flexibility	semi rigid
HW ± 20 %	1.8 mm
JO ± 10 %	13.00 mm
JW ± 20 %	1 mm
P ± 10 %	55 mm
R nom.	32.0 mm
R ± 10 %	32 mm
S nom.	13 mm
T ± 20 %	1 mm
V max.	3.3 mm
V ± 10 %	3 mm

Adhesive	VVO
Dielectric Strength	14 kV/mm
Dielectric Strength test method	ASTM D2671
ELV compliant (Article 4 - 2)	YES
Flammability	ASTM D635
Hazardous Goods	No
Min. Shrink Temperature - °C	+135 °C
Nato number	5970-99-300-9530
Operating Temperature	-75 °C to +150 °C
ROHS compliant	Yes
Shelf Life	5 years
Specifications	



GTIN-13 / EAN	5022660431883
Packaging 1 - Height (m)	0.035 m
Packaging 1 - Length (m)	0.13 m
Packaging 1 - Qty	1
Packaging 1 - Type	bag
Packaging 1 - Volume (m ³)	0.00046 m ³
Packaging 1 - Weight (kg)	0.007001 kg
Packaging 1 - Width (m)	0.1 m

More Information

UNSPSC Key	39121721
------------	----------

