 


Bottle Shapes, VG style

Art.-No. 401-57034 | 157-43-HW8-PO-X-BK | 




- Use in conjunction with circular grooved adaptors
- Strengthened strain relief by usage of an additional inner lip
- Excellent protection against environment impacts
- Eliminates moisture ingress to harness



More products in this product group:

[Bottle Shapes, VG style >](#)

Application	Heat shrinkable moulded shapes for use in Electrical and Electronic Cable Harness Applications.
Colour	Black (BK)
Material	Polyolefin, cross-linked (PO-X)
PART DESCRIPTION	157-43-HW8-PO-X-BK
Pack Content	1 pc.
Package Content packed in	bag
Product Family	Helashrink 150 Series, with rib
Product Group	Bottle Shapes, VG style
Type	157-43-HW8
Variant	For plug

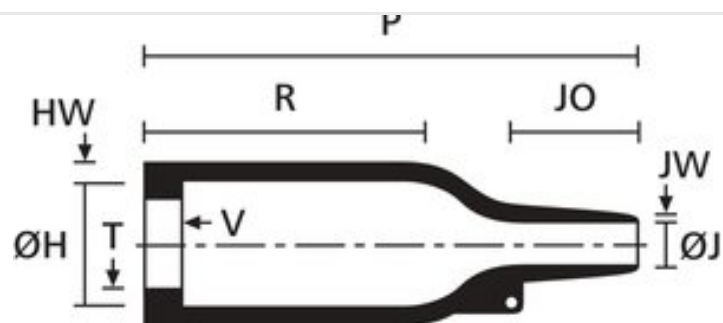

ØH max. b	28 mm
ØH min. a	43 mm
ØJ max. b	10 mm
ØJ min. a	43 mm
HW ± 20 %	2.2 mm
JW ± 20 %	1 mm
P ± 10 %	99 mm
R nom.	61 mm
R ± 10 %	61 mm
S nom.	20 mm
T ± 20 %	1.7 mm
V max.	3.3 mm
V ± 10 %	3 mm

Adhesive	VVO
ELV compliant (Article 4 - 2)	YES
Hazardous Goods	No
ROHS compliant	Yes
Shelf Life	5 years
Specifications	

Logistics and Packaging

GTIN-13 / EAN	5022660434334
Packaging 1 - Height (m)	0.13 m
Packaging 1 - Length (m)	0.2 m
Packaging 1 - Qty	1
Packaging 1 - Type	bag
Packaging 1 - Volume (m ³)	0.0013 m ³
Packaging 1 - Weight (kg)	0.000019 kg
Packaging 1 - Width (m)	0.05 m

More Information

UNSPSC Key	39121721
------------	----------



