

2-Way Outlet Shapes, VG style

Art.-No. 402-06037 | 206-1-GW24-PO-X-BK | 




- Mechanical tension relief in cable harnesses




More products in this product group:

[2-Way Outlet Shapes, VG style >](#)

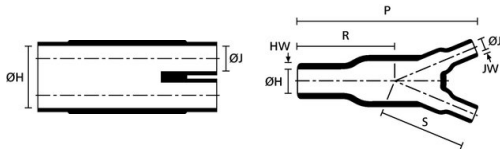

Application	Heat shrinkable moulded shapes for use in Electrical and Electronic Cable Harness Applications.
Colour	Black (BK)
Material	Polyolefin, cross-linked (PO-X)
PART DESCRIPTION	206-1-GW24-PO-X-BK
Pack Content	1 pc.
Package Content packed in	bag
Product Family	Helashrink 200 Series
Product Group	2-Way Outlet Shapes, VG style
Type	206-1-GW24
Variant	For 2-core cables

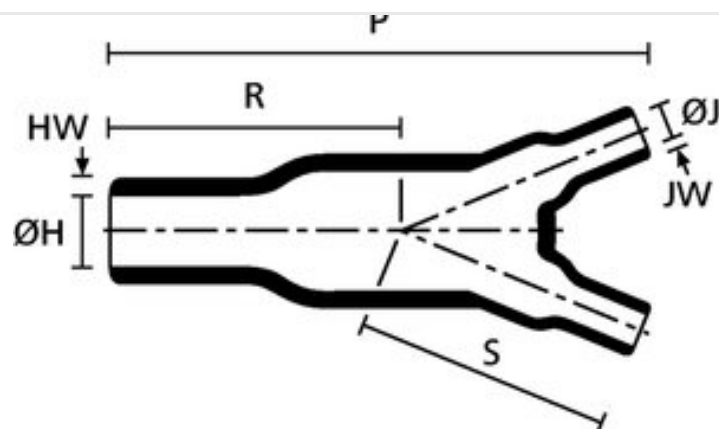

ØH max. b	6 mm
ØH min. a	13 mm
ØJ max. b	3 mm
ØJ min. a	7 mm
ØJ/K max. b	3 mm
ØJ/K min. a	7 mm
ØK max. b	3 mm
ØK min. a	7 mm
Flexibility	semi rigid
HW ± 20 %	1.5 mm
HW ± 30 %	1.5 mm
JW nom.	1 mm
JW ± 30 %	1.0 mm
JW/KW ± 30%	1 mm

R nom.	22 mm
R $\pm$ 10 %	19 mm
S nom.	19 mm

Specifications

Adhesive	W24
Dielectric Strength	15 kV/mm
Dielectric Strength test method	ASTM D2671
Flammability	ASTM D635
Min. Shrink Temperature - °C	+135 °C
Operating Temperature	-75 °C to +150 °C
ROHS compliant	Yes
Specifications	

GTIN-13 / EAN	5022660444371
Packaging 1 - Height (m)	0.015 m
Packaging 1 - Length (m)	0.130 m
Packaging 1 - Qty	1
Packaging 1 - Type	bag
Packaging 1 - Volume (m ³)	0.0002 m ³
Packaging 1 - Weight (kg)	0.0050 kg
Packaging 1 - Width (m)	0.100 m

More Information

UNSPSC Key	39121721
------------	----------