

2-Way Outlet Shapes, VG style

Art.-No. 402-03037 | 203-1-GW24-PO-X-BK | 




- Mechanical tension relief in cable harnesses



More products in this product group:

[2-Way Outlet Shapes, VG style >](#)

Application	Heat shrinkable moulded shapes for use in Electrical and Electronic Cable Harness Applications.
Colour	Black (BK)
Material	Polyolefin, cross-linked (PO-X)
PART DESCRIPTION	203-1-GW24-PO-X-BK
Pack Content	1 pc.
Package Content packed in	bag
Product Family	Helashrink 200 Series
Product Group	2-Way Outlet Shapes, VG style
Type	203-1-GW24
Variant	For 2-core cables

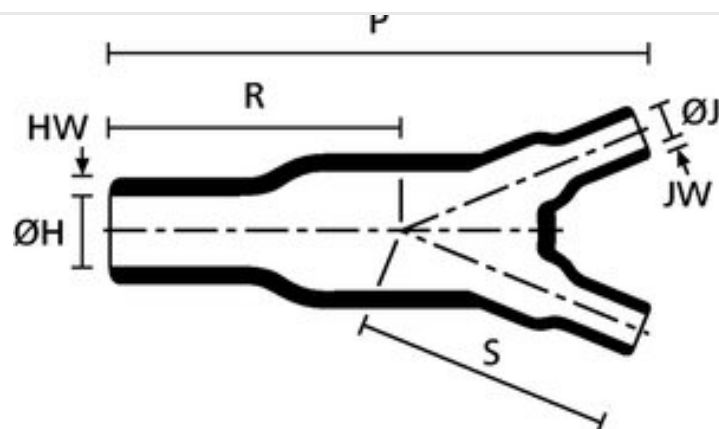

ØH max. b	12 mm
ØH min. a	27 mm
ØJ max. b	6 mm
ØJ min. a	13 mm
ØJ/K max. b	6 mm
ØJ/K min. a	13 mm
ØK max. b	6 mm
ØK min. a	13 mm
HW ± 30 %	2.5 mm
JW nom.	1.5 mm
JW/KW ± 30%	1.5 mm
P ± 10 %	80 mm
P ±10%=overall length	80 mm
R nom.	38 mm

Specifications

Adhesive	W24
Dielectric Strength	15 kV/mm
Dielectric Strength test method	ASTM D2671
Flammability	ASTM D635
Nato number	5970-12-308-5074
Operating Temperature	-75 °C to +150 °C
ROHS compliant	Yes
Specifications	

Logistics and Packaging

GTIN-13 / EAN	5022660443664
---------------	---------------

More Information

UNSPSC Key	39121721
------------	----------



