


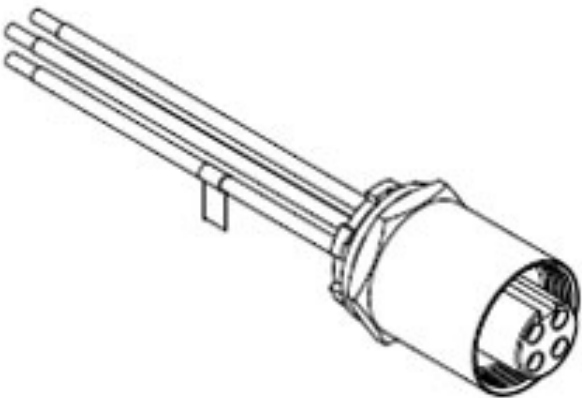

Part Number : [1300660134](#)
Product Description : BradPower D-Size (1 3/8"-M35) Brad Power Receptacle, 3 Poles, Female, 3/4"-14 NPT, 10 AWG, 0.5m (19.7") Length
Series Number : 130066
Status : Active
Product Category : Circular Industrial Connectors
Engineering Number : CR3C00A30M005



Documents & Resources

Drawings
[1300660134_sd.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	Not Relevant
EU ELV	Not Relevant
Low-Halogen Status	Not Reviewed per IEC 61249-2-21
REACH SVHC	Not Reviewed per D(2024)7663-DC (21 Jan 2025)
EU RoHS	Compliant with Exemption 6(c) per EU 2015/863

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

Part Details

General

Status	Active
Category	Circular Industrial Connectors
Series	130066
Description	BradPower D-Size (1 3/8"-M35) Brad Power Receptacle, 3 Poles, Female, 3/4"-14 NPT, 10 AWG, 0.5m (19.7") Length
IP Rating	IP67
Product Name	BradPower D-Size
Type	Single Ended (pigtail)
UPC	78678883696

Agency

UL	E258922
----	---------

Electrical

Current - Maximum per Contact	30.0A
Voltage - Maximum	600V

Physical

Coupling Type	Internal Thread
Gender	Female
Keyway	Single
Length	0.50m
Material - Component	Black Annodized Aluminum
Mounting Thread Size	3/4" - 14 NPT
Net Weight	369.028/g
Orientation	Straight
Panel Mount	Front
Poles	3
Temperature Range - Operating	-20° to +90°C
Wire/Cable Type	THHN

Wire Size (AWG)	10
-----------------	----