

Nylon (Polyamide) Locknut


**RoHS
Compliant**



Specifications

Material	: PA (Nylon), UL 94 V-2
Working temperature	: -40°C to 100°C
Colour	: Grey(RAL7035), Black(RAL9005), other colours customized.

Diagram

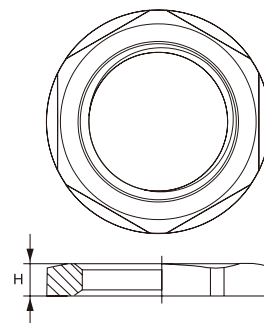

Specification Table

Part Number	Thread Size ØD1	H mm	Spanner mm
MP015347	M12 x 1.5	5	17
MP015348	M16 x 1.5	5	22
MP015349	M20 x 1.5	5.7	27
MP015350	M25 x 1.5	6	32
MP015351	M32 x 1.5	7	41
MP015352	M40 x 1.5	7	50
MP015353	M50 x 1.5	8.5	60
MP015354	M63 x 1.5	8	75
MP015355	M12 x 1.5	5	17
MP015356	M16 x 1.5	5	22
MP015357	M20 x 1.5	5.7	27
MP015358	M25 x 1.5	6	32

Part Number	Thread Size ØD1	H mm	Spanner mm
MP015359	PG 7	5	19
MP015360	PG 9	5	22
MP015361	PG 11	5	24
MP015362	PG 13.5	5.7	27
MP015363	PG 16	5.7	30
MP015364	PG 21	6	36
MP015365	PG 29	7	46
MP015366	PG 36	7.6	60
MP015367	PG 7	5	19
MP015368	PG 9	5	22
MP015369	PG 11	5	24
MP015370	PG 13.5	5.7	27


Nickle Plated Brass Locknut



Specifications

Material	: Nickel-plated brass
Working temperature	: -70°C to 200°C

Diagram

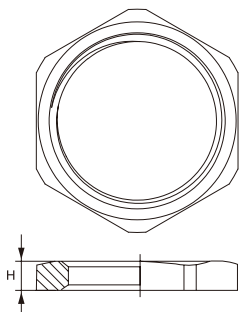

Specification Table

Part Number	Thread Size ØD1	H mm	Spanner mm
MP015371	M12 x 1.5	2.6	15
MP015372	M16 x 1.5	2.8	19
MP015373	M20 x 1.5	3.0	23
MP015374	M25 x 1.5	3.5	29
MP015375	M32 x 1.5	4	36
MP015376	M40 x 1.5	4.5	45
MP015377	M50 x 1.5	5.5	55
MP015378	M63 x 1.5	6	70
MP015379	PG 7	2.7	15

Part Number	Thread Size ØD1	H mm	Spanner mm
MP015380	PG 9	3	18
MP015381	PG 11	3	21
MP015382	PG 13.5	3	23
MP015383	PG 16	3	26
MP015384	PG 21	3.5	32
MP015385	PG 29	4	41
MP015386	PG 36	5	51
MP015387	PG 36	5	51

Part Number Table

Description	Part Number
Grey Nylon Polyamide Cable Gland Locknut, PK 10	MP015347
	MP015348
Grey Nylon Polyamide Cable Gland Locknut	MP015349
	MP015350
	MP015351
	MP015352
	MP015353
	MP015354
	MP015355
Grey Nylon Polyamide Cable Gland Locknut, PK 10	MP015356
	MP015357
Grey Nylon Polyamide Cable Gland Locknut	MP015358

Description	Part Number
Grey PG Type Nylon Polyamide Cable Gland Locknut, PK 10	MP015359
Grey PG Type Nylon Polyamide Cable Gland Locknut	MP015360
	MP015361
	MP015362
	MP015363
	MP015364
	MP015365
	MP015366
Black PG Type Nylon Polyamide Cable Gland Locknut	MP015367
	MP015368
	MP015369
	MP015370

Cable Gland Locknuts

multicompPRO

Description	Part Number
Metric Nickle plated Brass Cable Gland Locknut, PK 10	MP015371
Metric Nickle plated Brass Cable Gland Locknut	MP015372
	MP015373
	MP015374
	MP015375
	MP015376
	MP015377
	MP015378
PG Nickle plated Brass Cable Gland Locknut, PK 10	MP015379

Description	Part Number
PG Nickle plated Brass Cable Gland Locknut	MP015380
	MP015381
	MP015382
	MP015383
	MP015384
	MP015385
	MP015386
	MP015387

Important Notice : This data sheet and its contents (the "Information") belong to the members of the AVNET group of companies (the "Group") or are licensed to it. No licence is granted for the use of it other than for information purposes in connection with the products to which it relates. No licence of any intellectual property rights is granted. The Information is subject to change without notice and replaces all data sheets previously supplied. The Information supplied is believed to be accurate but the Group assumes no responsibility for its accuracy or completeness, any error in or omission from it or for any use made of it. Users of this data sheet should check for themselves the Information and the suitability of the products for their purpose and not make any assumptions based on information included or omitted. Liability for loss or damage resulting from any reliance on the Information or use of it (including liability resulting from negligence or where the Group was aware of the possibility of such loss or damage arising) is excluded. This will not operate to limit or restrict the Group's liability for death or personal injury resulting from its negligence. Multicomp Pro is the registered trademark of Premier Farnell Limited 2019.

Newark.com/multicomp-pro
Farnell.com/multicomp-pro
sg.element14.com/b/multicomp-pro

multicompPRO