


SPECIFICATIONS



Model Number: GL24S4H
Part Number: 032842

March 4, 2002

Mechanical Drawing:

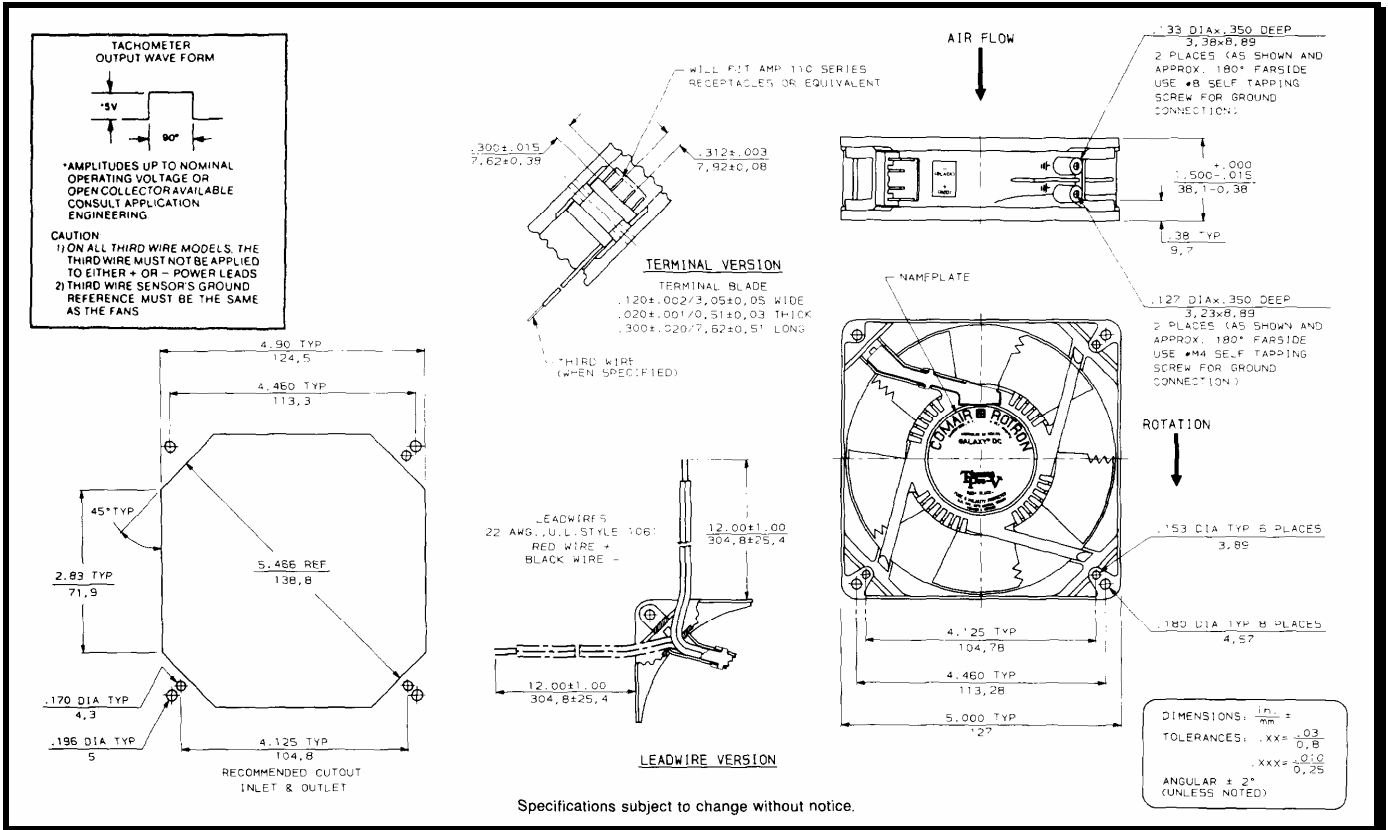

Motor:

Nominal Voltage = 24 vdc
 Operating Voltage Range = 12 - 24 vdc
 Nominal Running Current = .625 amps
 Locked Rotor Current = 1.15 amps
 Running Power = 15 watts
 Average Speed = 3200 RPM
 Air Flow @ 35 C = 150 CFM
 Bearings = Ball

Construction:

Venturi: Die Cast Zinc Alloy, Black.
 Propeller: Plastic, black, UL 94V-0.

Life Expectancy:

This fan is designed for continuous duty life of 82,500 hours at 50°C.

Additional Features:

Brushless DC Motor
 Locked Rotor Protection
 Automatic Restart Capability
 Reverse Polarity Protected
 Operating Temperature: -10°C to 70°C
 Storage Temperature: -40°C to 85°C
 Thermal Speed Control

Termination:

.110" Terminals
 PTC on 24" zip cord

Agency Approval:

UL, CSA, TUV