



[Home](#) : [Connectors](#) : [TNC](#) : EZ-240-TF-BH-X

EZ-240-TF-BH-X

Type TNC, female (jack), straight, EZ style connector for LMR[®]-240 and TCOM[®]-240 type cables. The EZ-240-TF-BH-X eliminates assembly errors and soldering with crimp-style outer contacts and spring finger inner contacts. It features a no-braid trim design, eliminating FOD and guaranteeing an optimal and consistent termination. The BeCu pins are designed to maximize surface contact and minimize current density. They provide a strong spring force making the EZ connectors a perfect choice for extreme cold and high-

vibration applications where the center conductor might contract. The TNC is a miniature, threaded, weatherproof connector with a contact design similar to a BNC series and a higher frequency performance.



Stock Code: **3190-8009**

TNC-female (jack)

Specifications

Part Number	EZ-240-TF-BH-X	Max Frequency (GHz)	8	Pin Finish	Gold
Stock Code	3190-8009	VSWR Freq	<1.35:1	Length (mm)	30.4
Interface	TNC	VSWR Frequency (GHz)	6	Length (in)	1.2
Gender	female (jack)	Coupling Nut	N/A	Width (mm)	11
Orientation	Straight	Inner Contact Attach	Spring Finger	Width (in)	0.43
				Weight (g)	30

PIM Rating		Outer Contact Attach	Crimp	Weight (lb)	0.07
Impedance (ohms)	50	Body Finish	Bi-Metal		


Compatible with

<u>LMR-240</u>	<u>LMR-240-DB</u>	<u>LMR-240-FR</u>
<u>LMR-240-MA</u>	<u>LMR-240-PVC</u>	<u>TCOM-240</u>
<u>TCOM-240-FR</u>		

Tools and Accessories



CST-240A

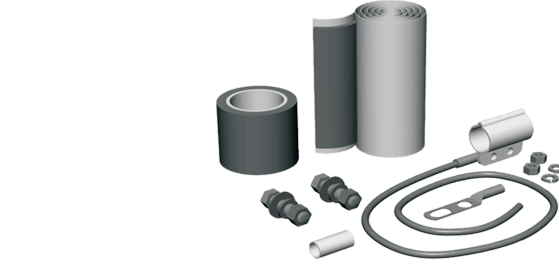

Grounding Kits



Weather S