 



CSB-M1281M1281

► SPLITTERS

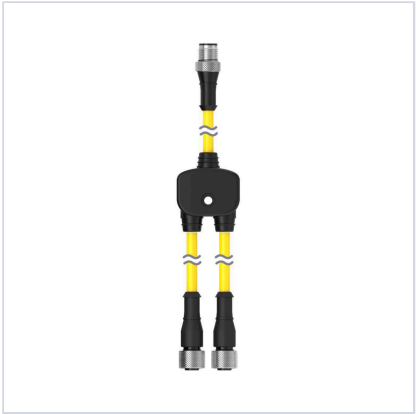

M12 QD Splitter Cable
8-pin Double-ended with 0.3 Female Branches and
Male Rotatable Trunk Connector; 0.3 m Trunk
Length
8X22 GA 1 ft Trunk 1 ft Branch
Part Number: 73252

SPECIFICATIONS

Trunk Length (m)	0.30
IP Rating	IP67
Shield/No Shield	No Shield
Branches: Connector Types	M12, M12
Branches: Number of Contacts	8, 8
Voltage Rating (V)	75 V ac/dc
Current Rating (A)	2.0
Number of Branches	2
Branches: Genders	Female, Female

Branches: Orientations	Straight, Straight
Wiring	Parallel
Splitter: Overmold Material and Color	PUR Black
Branches: Cable Jacket Material	PVC, PVC
Trunk: Cable Jacket Material	PVC
Trunk: Orientation	Straight
Trunk: Connector Type	M12
Minimum Temp. (Celsius)	-40
Trunk: Gender	Male
Maximum Temp. (Celsius)	105
Trunk: Number of Contacts	8