


# multicomp PRO

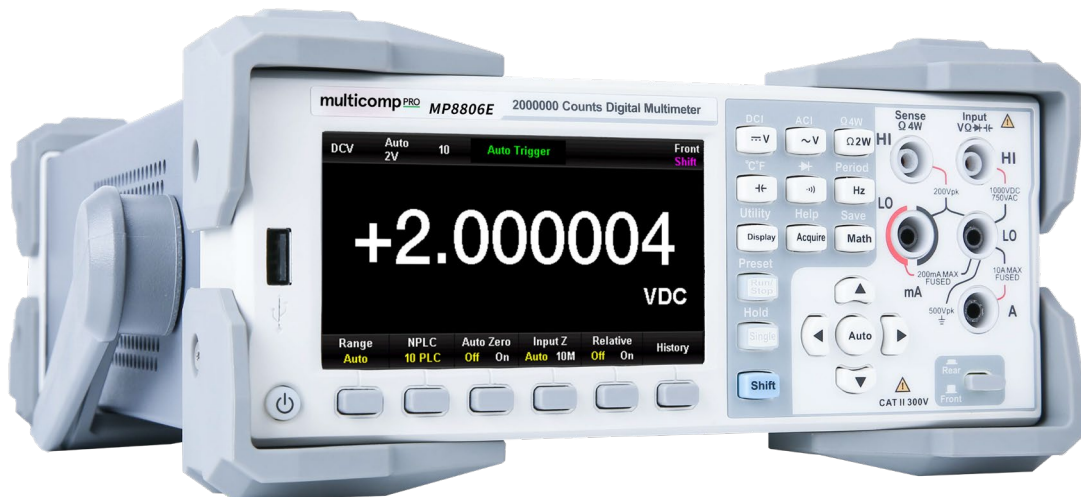

## BENCH TOP DIGITAL MULTIMETER SOFTWARE USER MANUAL MP8806E

# System Requirements

---

- 1GHz or higher CPU
- 1GB or more RAM
- Hard disk with 2GB or more free space USB 2.0/3.0

**The software supports the following operating**

**systems:** Microsoft Windows not lower than Vista

## Installation


---

 
1. Insert the installation CD into the CD-ROM of a computer.
2. The installation interface pops up. (If no installation interface appears, double-click Setup.exe in the CD-ROM directory to start it manually.)


# Using the Software

---

## 1. Scan Equipments

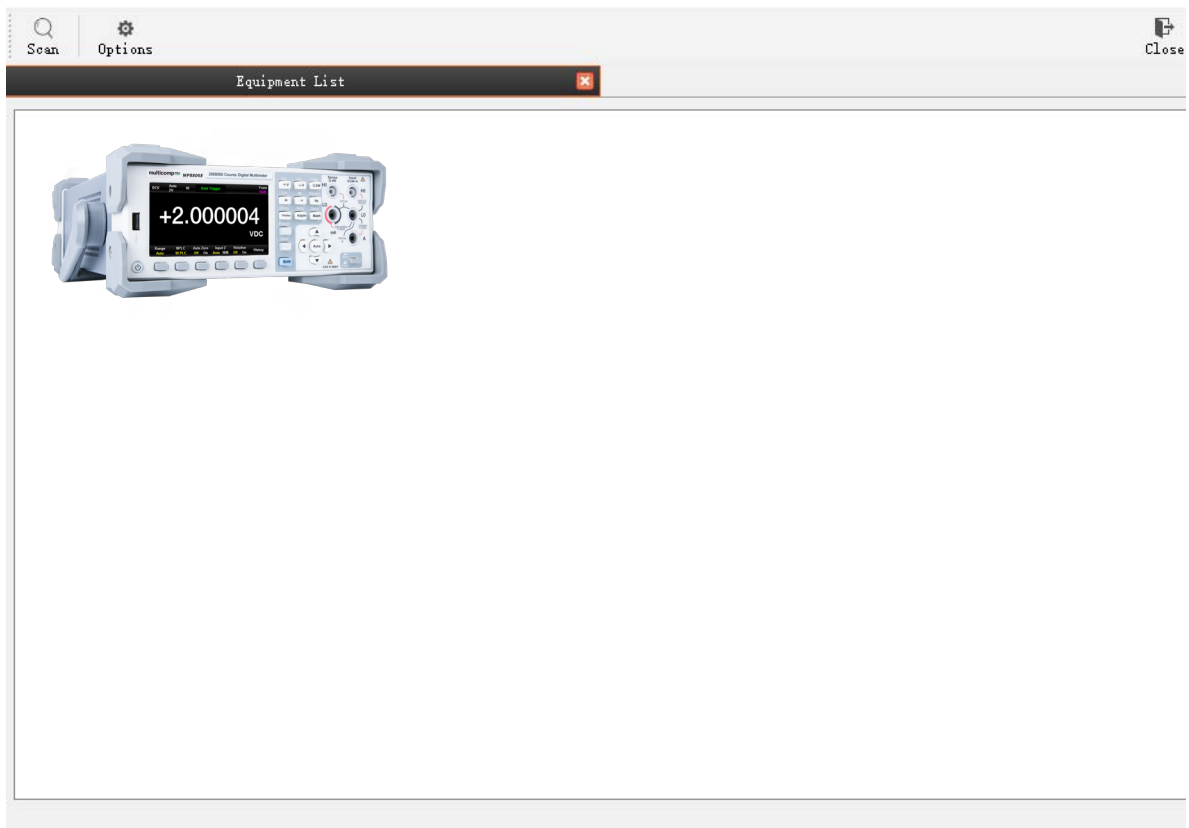


- Click  to scan equipments.
- Choose port type and click "OK" .

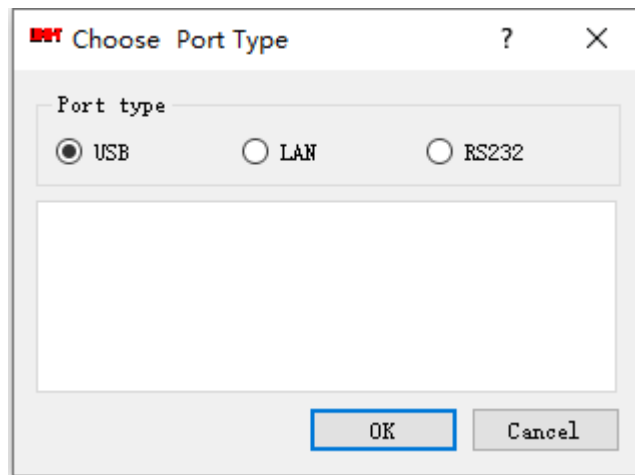


- Equipments will be added to the list.
- Choose a equipment and connect it.


## 2. Interface

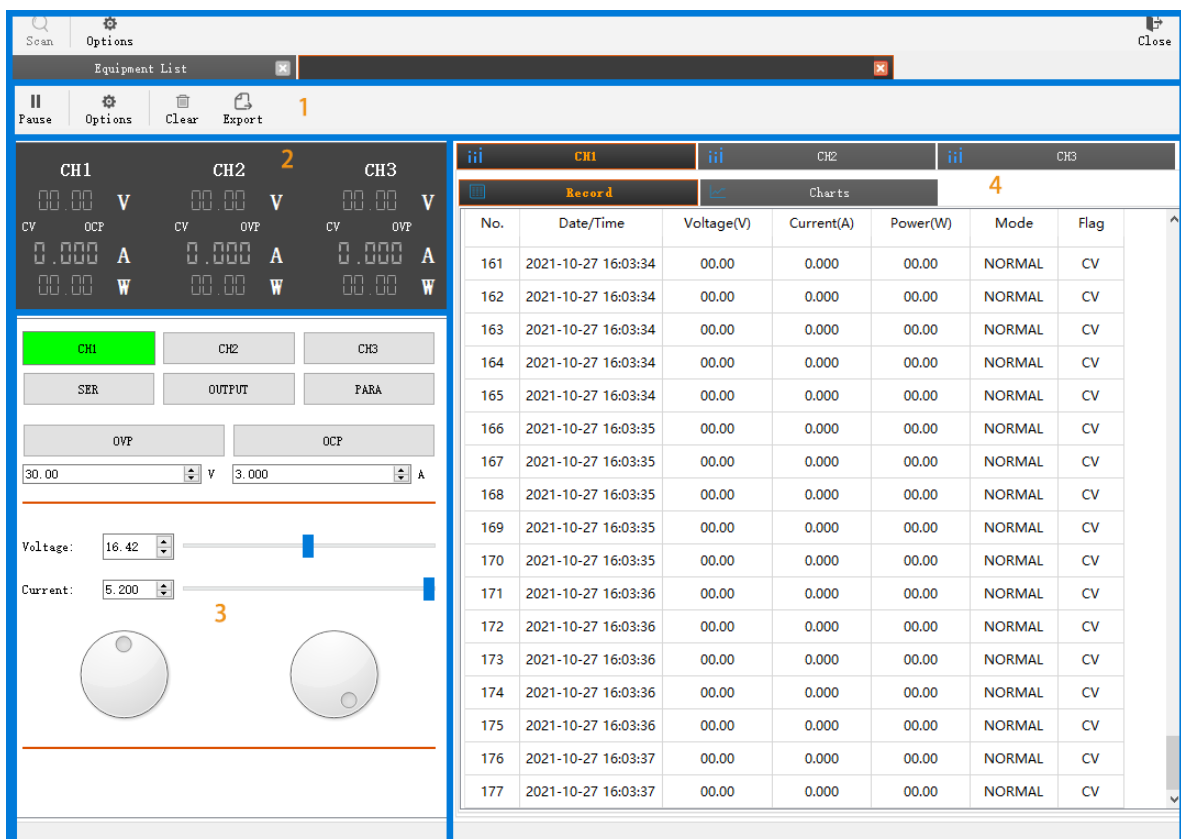


Area	Description
1	Toolbar
2	Real-time measurement
3	Control commands
4	Data record and chart

## 3. Export


- Click  in area 4 to export the data record to an Excel file


- Right click on the chart and select  Save to export the data chart to an Jpeg file

#### 4. Clear data

- Click  to clear the recorded data.

#### 5. Setup software


- Click  to open options dialog

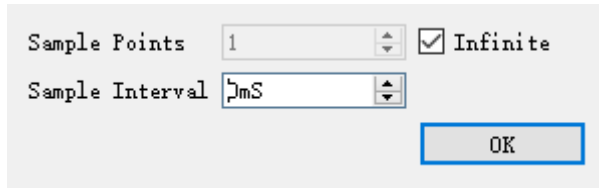


The Options dialog box contains two settings: 'Sample Points' with a value of 1 and an 'Infinite' checkbox which is checked; and 'Sample Interval' with a value of 1ms. An 'OK' button is located at the bottom right.

- "Sample Points": Set the number of sampling points. If "Infinite" is checked, the number is unlimited

#### 6. Get help

 - Click  to open the "Software User Manual"

#### 7. Close the software

- Click  to close the software