


K50PSAF1000RGB14Q

► K50 PROGRAMMABLE TOUCHLESS BUTTONS

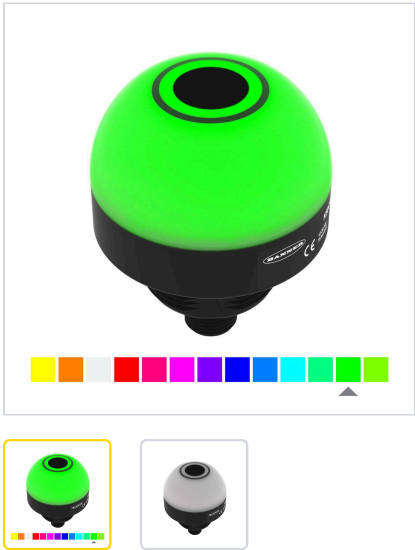

K50 Pro: 14-color RGB Adjustable-Field Sensor  
10-30 V dc; Polycarbonate; IP66, IP67, IP69K  
Input: Bimodal; Colors: Multicolor  
8-pin M12 Integral QD  
Part Number: 816244

CERTIFICATIONS



SPECIFICATIONS

Power	DC
IP Rating	IP66, IP67, IP69K
Display	No
Supply Voltage	10-30 V dc
Housing Style	Base Mount - Dome Window
Primary Housing Material	Polycarbonate
Indication	Yes
Actuation	Yes
Activation Function	Optical
Mounting Thread	M30 x 1.5
Color Input Control	Multiple (One or more wires/color, enables more colors than input wires)
Number of Colors	14
Product Size (mm)	50
Vibration Feedback	No
Color Technology	RGB Configurable
Color Option 1	RGB
Animation Option 1	Programmable
Connection	Integral QD

Quick Disconnect Type	M12
Max Current Color (mA)	220
Dimming Option	Programmable
Pick-to-Light Function	Programmable
Number of Input Pins/Conductors	8
Operation	Programmable
Output Type	Bipolar (NPN & PNP)
Input Type	Bimodal (PNP/NPN)
I/O Block Compatible	Yes
Max Input Response Time (ms)	250
Physical Dimensions (LxWxH or DxH mm)	50.0 x 66.0
Max Op. Relative Humidity Non-Condensing (%)	90% @ 50°C
High Temperature (up to 100&#176; C)	50
Min Op. Temperature (&#176;C)	-40
Storage Temp (&deg;C)	-40 to 70
Primary Housing Color	Black
Button Operation	Programmable
Primary Window Material	Polycarbonate Diffused
Feature: Washdown Rated	Yes
Feature: Encapsulated	No
Feature: Audible	No
Multi-Color Device	Simultaneous Colors On
Feature: Quick Disconnect	Yes
Pro-Editor Compatible (Discrete)	Yes

COMPATIBLE PRODUCTS

BRACKETS

<div><div>SMB30A</div><div>Bracket: Right-Angle Mounting Material: 12 Gauge Stainless Steel Curved mounting slot for versatility/orientation Clearance for M6 (1/4 in) hardware</div></div>
---

	<b>SMB30FA</b>  SMB30FA Bracket: Swivel with Tilt and Pan Movement 30 mm Mounting Hole 3/8-16x2in Bolt Thread Mount
	<b>SMB30FVK</b>  SMB30FVK Bracket: V-Clamp Flat with Fasteners for Mounting Sensor with 30 mm Threads to Pipe or Extrusions 32.6 mm (1.28 in)
	<b>SMB30MM</b>  Bracket: 30 mm Material: 12 Gauge Stainless Steel Curved mounting slot for versatility/orientation Clearance for M6 (1/4 in) hardware
	<b>SMB30RAVK</b>  Bracket: V-Clamp Mount 30 mm hole to 28 mm tube Right-angle
	<b>SMB30SC</b>  Bracket: Compact 30 mm Swivel Black reinforced thermoplastic polyester Wide Range of Articulation Hardware included
	<b>SMBAMS30P</b>  Bracket: 30 mm flat bracket Material: 12 Gauge Cold-Rolled Steel Curved mounting slot for versatility/orientation
	<b>SMBAMS30RA</b>  Bracket: 30 mm Right-Angle Material: 12 Gauge cold rolled steel Curved mounting slot for versatility/orientation

## PRO CONVERTER CABLE

	<b>PRO-KIT-ACC</b>  DK-Pro Series Accessory Kit Includes Converter Cable, Splitter Power Supply, WAGO Wire Nuts and M12 Double-Ended 8-pin to 5-pin Cordset
--	--

## LENS SHIELD COVERS

	<b>TC-K50-CL</b>  Accessory: K50 Touch Clear Field Cover Prevents unwanted activation of TOUCH button Material: Polycarbonate
--	---

**MISCELLANEOUS**

	<b>ACC-PRO-CABLE5</b>  Accessory: MQDMC-501 (1) WAGO WIRE NUT 2-POS LEVER (5)
--	--

**DOUBLE-ENDED CORDSETS**

	<b>MQDC-506-USB</b>  Converter Cable USB to Banner 1-WIRE 5-pin M12 For Banner Pro Series 0.7 m USB Cable; 1 m M12 Cable
	<b>MQDC-801-5M-PRO</b>  Cordset: Double-Ended M12 8-pin Straight Female; 5-pin Straight Male 0.3 m 4x22 Black PVC Jacket Nickel-Plated Brass Coupling Nuts

**SINGLE-ENDED CORDSETS**

	<b>MQDC-WDSS-0830</b>  Cordset: Single-Ended M12 8-pin Straight Female 9 m 8x24 Black PVC Jacket PVC Black; 316 Stainless Steel Coupling Nut
	<b>MQDC2S-806</b>  Cordset: Single-Ended M12 8-pin Straight Female 2.04 m 8x24 Shielded Black PVC Jacket Nickel-Plated Brass Coupling Nut
	<b>MQDC2S-815</b>  Cordset: Single-Ended M12 8-pin Straight Female 5.04 m 8x24 Shielded Black PVC Jacket Nickel-Plated Brass Coupling Nut
	<b>MQDC2S-830</b>  Cordset: Single-Ended M12 8-pin Straight Female 10.04 m 8x24 Shielded Black PVC Jacket Nickel-Plated Brass Coupling Nut

**SPLITTERS**

	<b>CSB-M1251FM1251M</b>  Splitter M12F to M12M and M12M connectors 5-pin, Non-Shielded, IP68, AWG 22 Black PVC Cord, Straight Connectors Trunk: 0.3 m; Branches: 0.3 m
--	---

OUTLET PLUG POWER SUPPLIES

	<p><b>PSW-24-1</b></p> <p>DC Power Supply - Wall Mount</p> <p>Input: 100-240 V ac 50/60 Hz: Multi-blade outlet plug</p> <p>Output: 24 V dc 1 A; 2 m (6.5 ft) 5-pin M12 QD</p> <p>UL Listed Class 2</p>
--	--