

RoHS  
Compliant




Larger



Hemispherical



Cylindrical

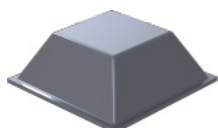

Square

## Description

Strong, Flexible & Highly Resilient. Among their many features is the ability to withstand shock and vibration, whilst being both non-slip and non-marking. Large range of profiles, sizes & colours, supplied kiss-cut on a sheet to allow ease of removal during application. High tack age resistant acrylic adhesive. When applying to Glass or Clear plastics, the unique transparent polyurethane provides superior clarity and a more chameleon effect.

## Features

- No-Slip & Non-Marking
- Durable & Resilient
- Shock & Vibration Resistant
- Reduces Noise & Vibration
- Feet, Spacers, Stops for Domestic Appliances.
- Feet for raising Electronic, Audio, Video equipment to prevent overheating
- Feet and Spacers for Raspberry Pi Boxes, Electronic Enclosures
- Supports for Glass Shelving, Glassware & Glass Top Furniture

## Polyurethane Information

Properties	Test Method	Clear	Coloured
Hardness (Shore A)	ASTN D-2240	66-70	66-70
Tensile Strength (MPa)	BS903	4.5MN/m <sup>2</sup>	4.5MN/m <sup>2</sup>
Elongation (%)	BS903	193	193
Tear Strength (KN/m)	BS903	14.4	14.4
Abrasion Resistance (MG loss)	BS EN 5470-1:1999	150	150
Flame Retardancy	UL94HB (in house test)	Pass	Pass

Shelf-Life - 12 months when stored in original packaging at room temperature

**Exposure to the Environment** Bumperstops are intended for interior applications where physical properties will remain unchanged. When used externally for extended periods, some discoloration as well as loss of adhesion may occur.

## Adhesive Information

Adhesive Type	Long ageing High Tack Acrylic
Adhesive Shear Stainless Steel - 20min - 23°C 50% RH	Peel FINAT 1 Unit N/25mm - 16N
Adhesive Shear Stainless Steel - 24h - 23°C 50% RH	Peel FINAT 1 Unit N/25mm - 15.7
Temperature Application	20°C to 40°C
Application Temperature	-20°C to + 120°C

**Part Number Table**

Description	Part Number
Feets, Hemispherical Shape, Self Adhesive, Clear, 8mm × 2.2mm, 140Pcs	MP2008-CL1-140
Feets, Hemispherical Shape, Self Adhesive, Clear, 8mm × 2.2mm, 4Pcs	MP2008-CL1-4
Feets, Hemispherical Shape, Self Adhesive, Clear, 10mm × 3.1mm, 48Pcs	MP2010-CL1-48
Feets, Hemispherical Shape, Self Adhesive, Clear, 11.1mm × 5mm, 55Pcs	MP2115-CL1-55
Feets, Hemispherical Shape, Self Adhesive, Black, 11.1mm × 5mm, 55Pcs	MP2115-BK1-55
Feets, Hemispherical Shape, Self Adhesive, Grey, 11.1mm × 5mm, 55Pcs	MP2115-GY1-55
Feets, Hemispherical Shape, Self Adhesive, Black, 16mm × 7.9mm, 40Pcs	MP2150-BK1-40
Feets, Hemispherical Shape, Self Adhesive, Grey, 16mm × 7.9mm, 40Pcs	MP2150-GY1-40
Feets, Hemispherical Shape, Self Adhesive, Grey, 19mm × 9.5mm, 42Pcs	MP2190-BK1-42
Feets, Cylindrical Shape, Self Adhesive, Black, 8mm × 3mm, 60Pcs	MP2075-BK1-60
Feets, Cylindrical Shape, Self Adhesive, Clear, 12.7mm × 3.5mm, 60Pcs	MP2125-CL1-60
Feets, Cylindrical Shape, Self Adhesive, Black, 12.7mm × 3.5mm, 60Pcs	MP2125-BK1-60
Feets, Cylindrical Shape, Self Adhesive, Grey, 12.7mm × 3.5mm, 60Pcs	MP2125-GY1-60
Feets, Cylindrical Shape, Self Adhesive, Black, 16.5mm × 10.2mm, 40Pcs	MP2164-BK1-40
Feets, Cylindrical Shape, Self Adhesive, Black, 19mm × 4mm, 28Pcs	MP2024-BK1-28
Feets, Cylindrical Shape, Self Adhesive, Grey, 19mm × 4mm, 28Pcs	MP2024-GY1-28
Feets, Cylindrical Shape, Self Adhesive, Black, 20mm × 6.2mm, 28Pcs	MP2020-BK1-28
Feets, Larger Shape, Self Adhesive, Black, 22.3mm × 10.1mm, 48Pcs	MP2210-BK1-48
Feets, Larger Shape, Self Adhesive, Grey, 22.3mm × 10.1mm, 48Pcs	MP2210-GY1-48
Feets, Larger Shape, Self Adhesive, Black, 20.6mm × 13.2mm, 24Pcs	MP3206-BK1-24
Feets, Larger Shape, Self Adhesive, Grey, 20.6mm × 13.2mm, 24Pcs	MP3206-GY1-24
Feets, Square Shape, Self Adhesive, Black, 10mm × 2.5mm, 55Pcs	MP2100-BK1-55
Feets, Square Shape, Self Adhesive, Grey, 10mm × 2.5mm, 55Pcs	MP2100-GY1-55
Feets, Square Shape, Self Adhesive, Black, 12.7mm × 3.1mm, 80Pcs	MP2127-BK1-80
Feets, Square Shape, Self Adhesive, Grey, 12.7mm × 3.1mm, 80Pcs	MP2127-GY1-80
Feets, Square Shape, Self Adhesive, Black, 12.6mm × 5.7mm, 40Pcs	MP2126-BK1-40
Feets, Square Shape, Self Adhesive, Grey, 12.6mm × 5.7mm, 40Pcs	MP2126-GY1-40
Feets, Square Shape, Self Adhesive, Black, 20.5mm × 7.5mm, 36Pcs	MP2205-BK1-36
Feets, Square Shape, Self Adhesive, Grey, 20.5mm × 7.5mm, 36Pcs	MP2205-GY1-36

**Important Notice :** This data sheet and its contents (the "Information") belong to the members of the AVNET group of companies (the "Group") or are licensed to it. No licence is granted for the use of it other than for information purposes in connection with the products to which it relates. No licence of any intellectual property rights is granted. The Information is subject to change without notice and replaces all data sheets previously supplied. The Information supplied is believed to be accurate but the Group assumes no responsibility for its accuracy or completeness, any error in or omission from it or for any use made of it. Users of this data sheet should check for themselves the Information and the suitability of the products for their purpose and not make any assumptions based on information included or omitted. Liability for loss or damage resulting from any reliance on the Information or use of it (including liability resulting from negligence or where the Group was aware of the possibility of such loss or damage arising) is excluded. This will not operate to limit or restrict the Group's liability for death or personal injury resulting from its negligence. Multicomp Pro is the registered trademark of Premier Farnell Limited 2019.