


# PXP4003/002/03P Datasheet

**Product Name // Pre-wired Inline Cable Connector - Right Angle - 2m - 3 Contacts - Plug**

 [View Product Page](#)

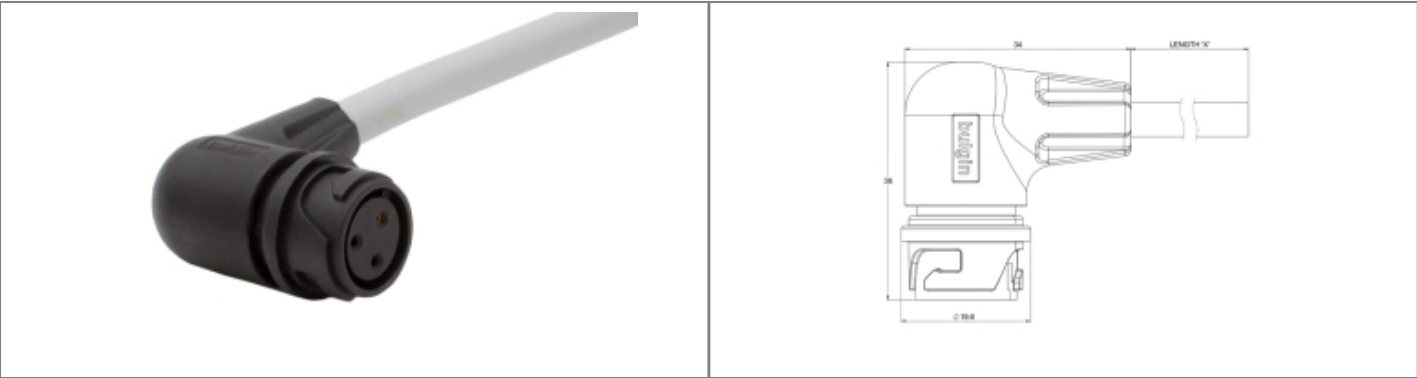

**// Product Description:**

- Pre-Wired Inline Cable Connector - Right Angle
  - Water and dustproof to IP68 when mated with compatible connector
  - 4000 Series Buccaneer to blunt cut wire
  - 2m Cable Length
- 3 Contacts - Plug
  - Sealing Cap available separately to maintain IP rating of unmated connectors
  - Mates with flex cable connectors

**// General Information:**

|                                 |                                                                         |
|---------------------------------|-------------------------------------------------------------------------|
| Product Display Title:          | Pre-wired Inline Cable Connector - Right Angle - 2m - 3 Contacts - Plug |
| Product Family:                 | Circular Power Connectors                                               |
| Product Series:                 | 4000 Series Buccaneer                                                   |
| Approvals:                      | cUL, UL, VDE                                                            |
| Body Colour:                    | Black                                                                   |
| Body Material:                  | Polyamide (PA)                                                          |
| Body Material Type:             | Plastic Body                                                            |
| Cable Length:                   | 2m                                                                      |
| Contact Type:                   | Plug Contact                                                            |
| Coupling Type:                  | Bayonet Lock                                                            |
| Current Max:                    | 13A                                                                     |
| Diameter Over Coupling Ring Mm: | 19.7mm                                                                  |
| Flamability Rating:             | UL94V-0                                                                 |
| Function:                       | Inline Cable Connector                                                  |
| Ip Rating:                      | IP66, IP67, IP68                                                        |
| Max Operating Temperature:      | +120°C                                                                  |
| Min Operating Temperature:      | -30°C                                                                   |
| Number Of Contacts:             | 3 Contacts                                                              |
| Rohs Compliant:                 | Yes                                                                     |
| Voltage Max:                    | 600V                                                                    |

**// Product PDF Links**



**// Product 3D CAD Model Links**

