


PXP4003/010/12P Datasheet

Product Name // Pre-wired Inline Cable Connector - Right Angle - 10m - 12 Contacts - Plug

 [View Product Page](#)

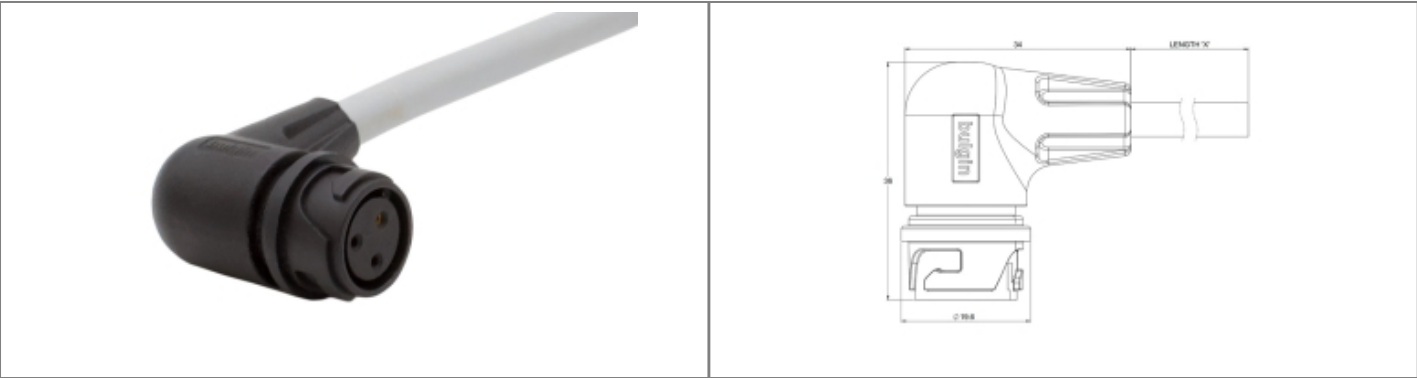

// **Product Description:**

- Pre-Wired Inline Cable Connector - Right Angle
 - Water and dustproof to IP68 when mated with compatible connector
 - 4000 Series Buccaneer to blunt cut wire
 - 10m Cable Length
- 12 Contacts - Plug
 - Sealing Cap available separately to maintain IP rating of unmated connectors
 - Mates with flex cable connectors

// **General Information:**

Product Display Title:	Pre-wired Inline Cable Connector - Right Angle - 10m - 12 Contacts - Plug
Product Family:	Circular Power Connectors
Product Series:	4000 Series Buccaneer
Approvals:	cUL, UL, VDE
Body Colour:	Black
Body Material:	Polyamide (PA)
Body Material Type:	Plastic Body
Cable Length:	10m
Contact Type:	Plug Contact
Coupling Type:	Bayonet Lock
Current Max:	3A
Diameter Over Coupling Ring Mm:	19.7mm
Flamability Rating:	UL94V-0
Function:	Inline Cable Connector
Ip Rating:	IP66, IP67, IP68
Max Operating Temperature:	+120°C
Min Operating Temperature:	-30°C
Number Of Contacts:	12 Contacts
Rohs Compliant:	Yes
Voltage Max:	160V

// **Product PDF Links**

 [4000 Series power connectors...](#)

// **Product 3D CAD Model Links**

 [PXP4003/010/12P3D CAD Model](#)



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)