


PXP4003/015/02S Datasheet

Product Name // Pre-wired Inline Cable Connector - Right Angle - 15m - 2 Contacts - Socket

 [View Product Page](#)

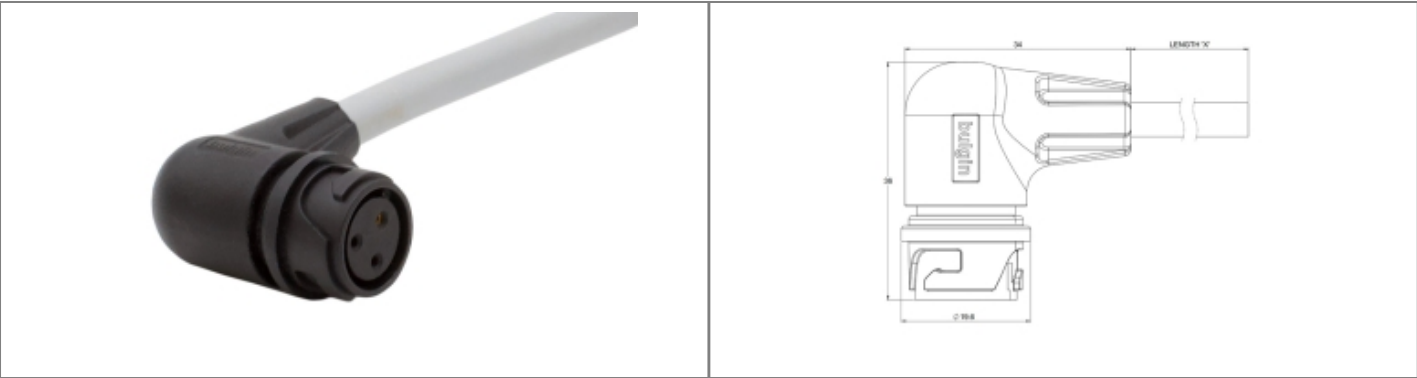

// Product Description:

- Pre-Wired Inline Cable Connector - Right Angle
 - Water and dustproof to IP68 when mated with compatible connector
 - 4000 Series Buccaneer to blunt cut wire
 - 15m Cable Length
- 2 Contacts - Socket
 - Sealing Cap available separately to maintain IP rating of unmated connectors
 - Mates with flex cable connectors

// General Information:

Product Display Title:	Pre-wired Inline Cable Connector - Right Angle - 15m - 2 Contacts - Socket
Product Family:	Circular Power Connectors
Product Series:	4000 Series Buccaneer
Approvals:	cUL, UL, VDE
Body Colour:	Black
Body Material:	Polyamide (PA)
Body Material Type:	Plastic Body
Cable Length:	15m
Contact Type:	Socket Contact
Coupling Type:	Bayonet Lock
Current Max:	13A
Diameter Over Coupling Ring Mm:	19.7mm
Flamability Rating:	UL94V-0
Function:	Inline Cable Connector
Ip Rating:	IP66, IP67, IP68
Max Operating Temperature:	+120°C
Min Operating Temperature:	-30°C
Number Of Contacts:	2 Contacts
Rohs Compliant:	Yes
Voltage Max:	600V

// Product PDF Links



// Product 3D CAD Model Links



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)