


P.V.C. Insulated P.V.C. Sheathed Flexible Cords 300/500V

Reference:	3192Y	Twin Flat	H05VVH2-F
	318_Y	Multi Core Round	H05VV-F
	309_Y	Multi Core Round	H05V2V2-F

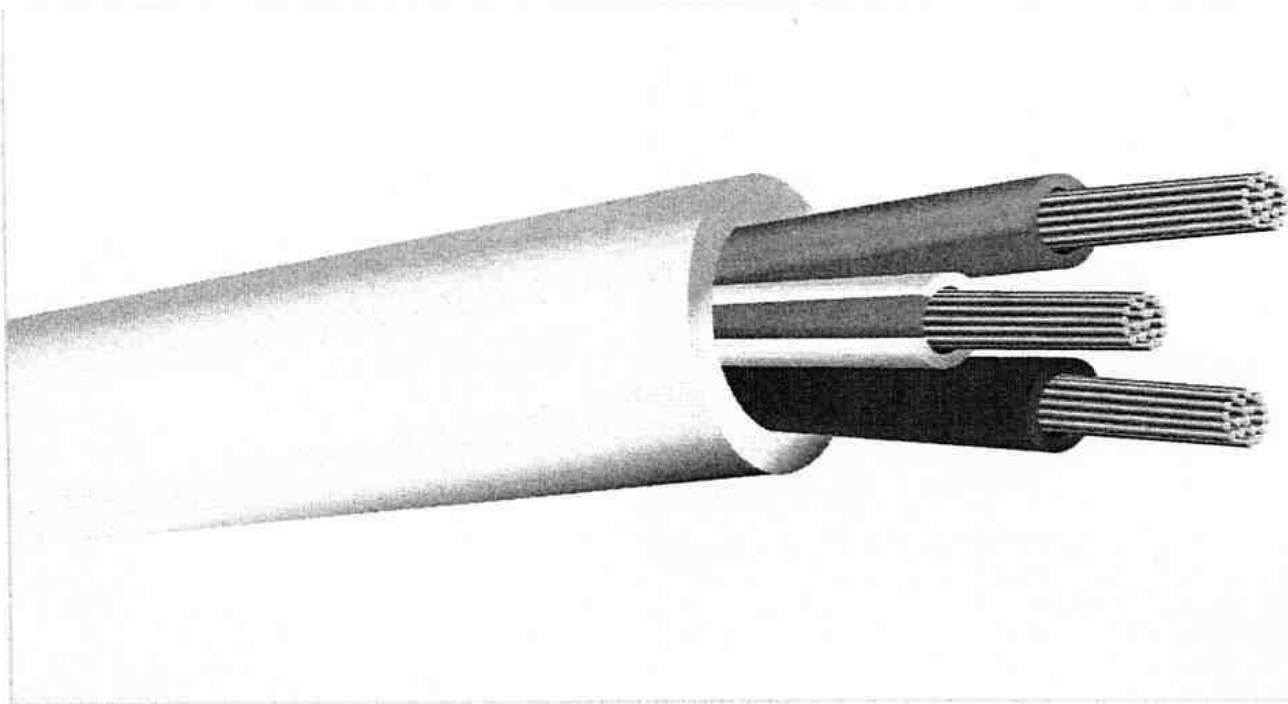

Manufactured to: IS 201 or BS6500 HD21

Conductor mm ²	Conductor Construction	Mean Overall Dimensions (mm)					Conductor resistance ohms/km @ 20°C
		Flat 2 Core	2 Core Circular	3 Core Circular	4 Core Circular	5 Core Circular	
{0.5	16 / 0.20	4.0 × 6.10	6.10	6.50	-	-	39.0
0.75	24 / 0.20	4.15 × 6.5	6.50	6.70	7.60	8.60	26.0
1.0	32 / 0.20	-	6.50	7.05	8.15	9.40	19.50
{1.25	40 / 0.20	-	7.50	8.05	-	-	15.60
1.5	30 / 0.25	-	7.80	8.25	9.60	10.60	13.30
2.5	50 / 0.25	-	9.25	10.20	11.30	-	7.98
*4.0	56 / 0.30	-	-	11.50	12.80	-	4.95

{ Are not standard approved sizes

* 4mm² size is covered in BS7919

Colours: White and Black Sheath. Other colours available on request

Packaging: 50 and 100 metre lengths. Other lengths available on request.