


DATA SHEET

1. Date – 2025-07-30
2. Part Number – 35RHHL220MD11
3. Dimension

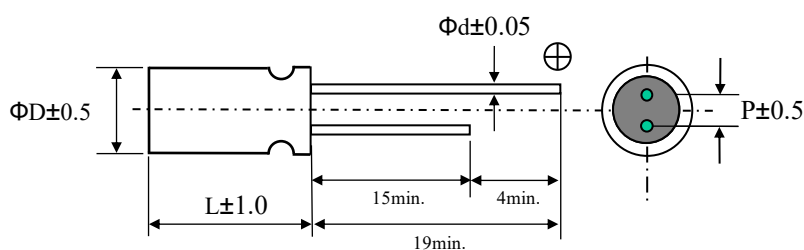

[mm]	
ΦD	8.0
L	11.5
Φd	0.6
P	3.5

Temperature range	-55 to +125 °C
Rated Voltage	35V
Surge Voltage	40.25V
Capacitance at 20 °C, 120Hz	220 μ F
Capacitance tolerance at 20 °C, 120Hz	-20 to +20% [M]
Tangent of loss angle (tan δ) at 20 °C, 120Hz	12%
Leakage current after 2 minutes	231 μ A
E.S.R max. at 20 °C, 100kHz	21 m Ω
Endurance at 125 °C	4000hrs
Rated ripple current at 125 °C, 100kHz	3300mA rms

* All products are lead free, RoHS compliance and Halogen free

** Automotive products are IATF 16949 certified

*** AEC-Q200 compliant

VINA EneSol Co., Ltd.

Manufacturer of the aluminum polymer capacitors (EneCap™)

Technical Research Center