


# Palm/Foot Switches

## Range: Control Stations

Order Code: SFP-EAM-1A1B-RD/HYL01 (1DE.SP.21NR)

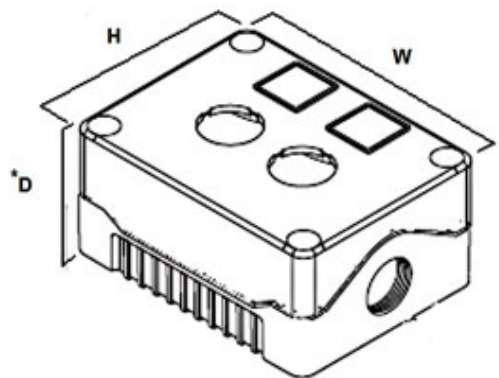

\*Enclosure only except 1DE.SP series where D includes actuator height

### DESCRIPTION

Palm/foot switch red button. Push to stop/start - release to reset

### CONTROL STATIONS FEATURES

- Customised control station service available - please ask for details.
- Insulation resistance -  $>100\text{M}\Omega$  @ 500VDC
- Enclosures sealed up to IP66
- Dust & waterproof for short-term submersion
- 4 sizes available! Accepting 1-4 push button switches
- 2 contact blocks fitted as standard
- Different voltage ratings are available
- Contact material - Silver Bifurcated and serrated
- Operating Temperature  $-10$  to  $+65^{\circ}\text{C}$
- Contact rating - AC12 Resistive / AC15 Electromagnetic - 240V (3A) / 415V (1.5A)
- Mechanical life - 1 million operations

*Features may vary by product throughout the range.*

*Subject to technical modification without notice.*

*Typographical and other errors do not justify claim for damages.*

## SPECIFICATION

|                           |                            |
|---------------------------|----------------------------|
| Base Colour               | Black                      |
| Base Style                | Standard base              |
| Depth (mm)                | 102.5                      |
| Enclosure Material        | ABS-UL94-HB                |
| Height (mm)               | 85                         |
| IP Rating                 | IP66                       |
| Lid Colour                | Grey                       |
| Min Temperature Rating °C | -10                        |
| Max Temperature Rating °C | 65                         |
| Number of Switches        | 1                          |
| Size (mm)                 | 85x69x102.5                |
| Switch 1 Style            | Pushbutton non-illuminated |
| Switch 1 Substyle         | Palm/foot                  |
| Width (mm)                | 69                         |