


PXV0777/4POLE/04 Datasheet

Product Name // Vitalis Buccaneer Inline Sealed Cable
Joiner Range (4 Way Terminal Block)

 [View Product Page](#)

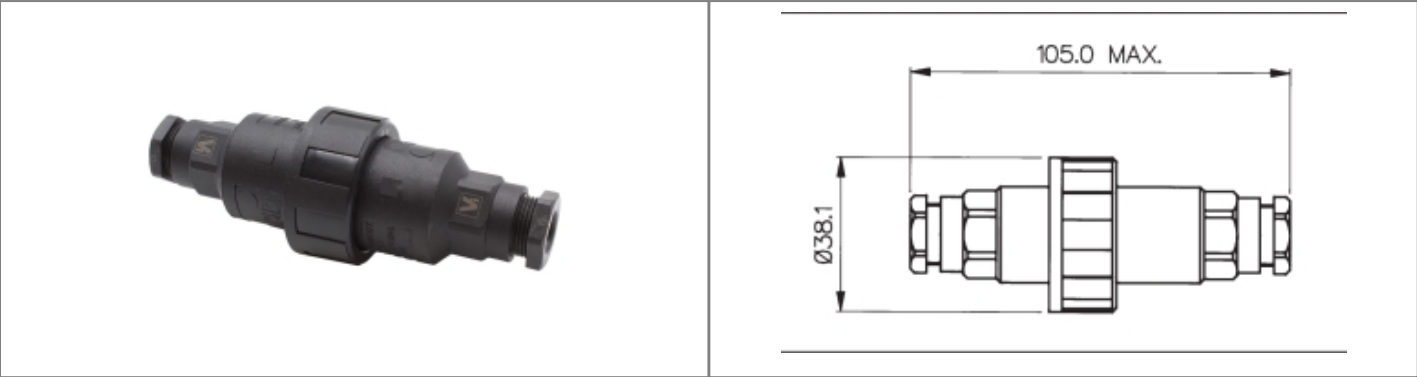

// Product Description:

- ⬢ PXV0777/4POLE/04 provides a PCF reduction of 8.2 kg CO₂e per 100 units compared to the equivalent Standard Series Buccaneer part number
 - ⬢ Sealed Cable Joiner
 - ⬢ Water and dustproof to IP68 when mated
 - ⬢ Supplied with 4-way terminal block
- ⬢ 3.5mm-5mm diameter cable acceptance
 - ⬢ Cable Glands for differing cable diameters available separately individually or in packs
 - ⬢ Cable Support accessory 12237/R available separately

// General Information:

Product Display Title:	Vitalis Buccaneer In-Line Sealed Cable Joiner Range (4 Way Terminal Block)
Product Family:	Circular Power Connector
Product Series:	Standard Vitalis Buccaneer
Body Colour:	Black
Body Material:	Polyamide (PA)- Glass Filled
Body Material Type:	Plastic Body
Contact Type:	Terminal Block
Coupling Type:	Screw
Current Max:	10A
Diameter Over Coupling Ring Mm:	38.1mm
Flamability Rating:	UL94V-0
Function:	Flex to Inline Sealed Cable Joiner
Ip Rating:	IP68, IP69K
Max Cable Entry Size:	5mm
Min Cable Entry Size:	3.5mm
Max Operating Temperature:	+70°C
Min Operating Temperature:	-20°C
Number Of Contacts:	4 Contacts
Rohs Compliant:	Yes
Voltage Max:	250V

// Product PDF Links

 [Standard Vitalis Buccaneer Product...](#)

// Product 3D CAD Model Links

 [PXV0777/4POLE/043D CAD Model](#)