

# 2mm IDC CABLE STRIPS TCMD SERIES

Mates with:  
SMM\*, MMS\*

## SPECIFICATIONS

For complete specifications see [www.samtec.com](http://www.samtec.com)?TCMD

**Insulator Material:**

Black Glass Filled Polyester



**Terminal:**

Phosphor Bronze

**Plating:** Sn over 50µ" (1,27µm) Ni

**Wire:**

28 AWG 7/36 Stranded, Tinned, Copper with Gray PVC Insulator

**Current Rating:**




1A

**Operating Temp Range:**

-40°C to +105°C


**RoHS Compliant:**

Yes

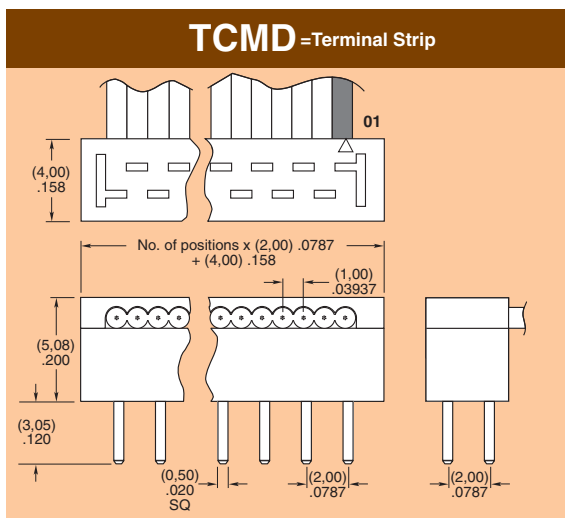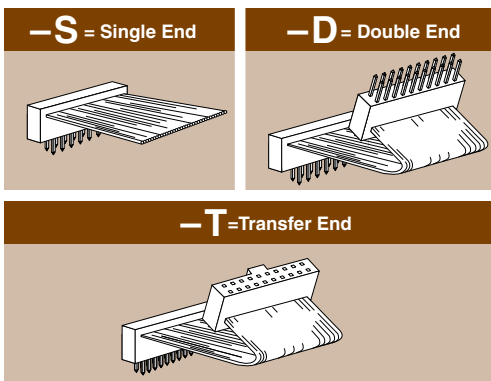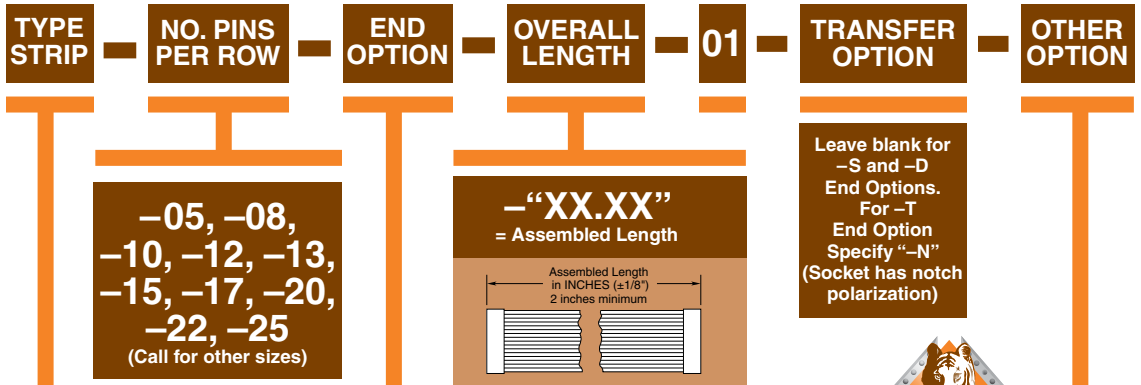

\*Note: Standard TCMD callout will not mate with SMM, MMS. Must use gold plated callouts. See drawing on web.

Note: TCMD Series assemblies are non-standard, non-returnable.

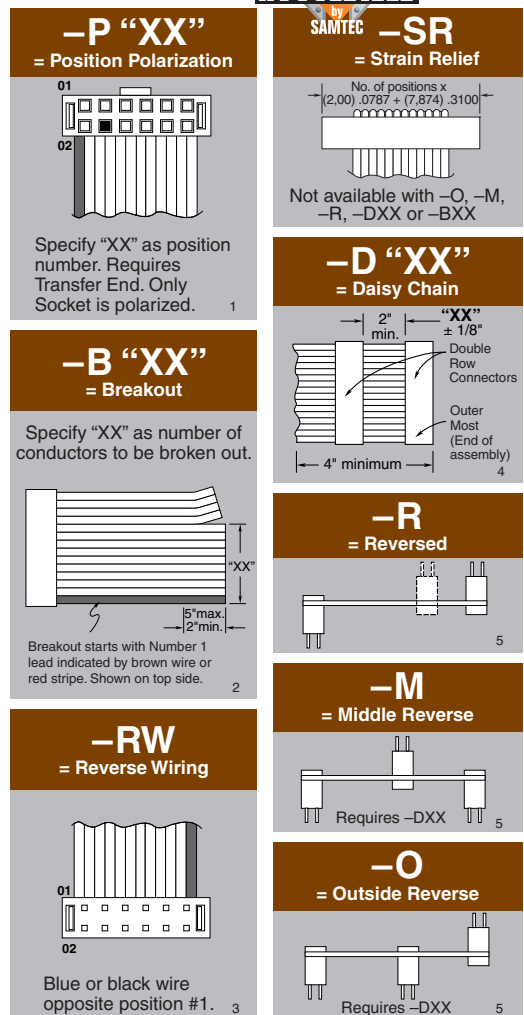

Due to technical progress, all designs, specifications and components are subject to change without notice.