


RoHS Compliant



UC-607

uPCI 2xRS232 230K

"SERIAL CARDS ENGINEERED TO EXCEED EXPECTATIONS"

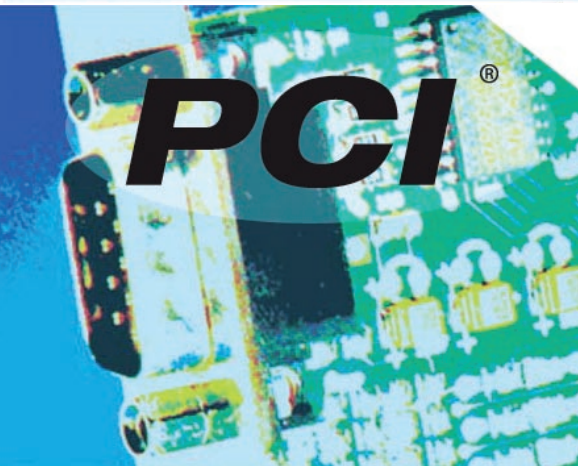

Description

Universal PCI card provides 2 industry standard 9 pin RS232 serial COM ports in a single PCI slot, capable of baud rates up to 230,400.

Universal PCI is fully compatible with both 3.3Volt and 5Volt PCI slots.

With Brainboxes industry renowned Lifetime Warranty and Lifetime Support!

Features

- 2 port RS232
- PCI 3.0
- 128 Byte Tx and 128 Byte Rx FIFOs
- Up to 230,400 Baud
- DB9 connector (9 Pin Male)
- Drivers for all popular operating systems
- Sample Programs, Test & Terminal software
- Lifetime Support
- Lifetime Warranty (registration required)

Options



UC-607:
uPCI 2xRS232 230K

Software

Microsoft signed drivers (easy installation & robust operation) for:

- Windows Server 2008 & Windows 2000
- Windows Vista 32 bit and 64 bit editions
- Windows Server 2003 32 bit & 64 bit Editions
- Windows XP 32 bit & 64 bit editions



As well as: full product documentation, a thorough troubleshooting guide and terminal software. Detailed sample source code for many popular programming languages. Further OS support on next page.



ORDER

Description
uPCI 2xRS232 230K


 




Code
UC-607

Alternative baud rates see UC-257 & UC-302

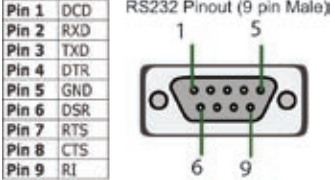

uPCI 2xRS232 230K

UC-607: Full Specification

Port 	Ports Connector FIFO size Operating Distance Cable	2 x RS232 DB9 connector (9 Pin Male) 128 RX FIFO + 128 TX FIFO EIA - RS232 Standard No Cable; Integrated Connector
Port Settings 	Baud Rate Data Bits Parity Stop Bits Flow Control Tx/Rx Modes	230,400 5,6,7 or 8 Odd, Even, None, Mark or Space 1, 1.5 or 2 RTS/CTS DSR/DTR XON/XOFF Point to Point
Interface 	OS Compatibility BUS	Windows Server 2008 32 bit & 64 bit Editions Windows Vista 32 bit & 64 bit Editions Microsoft Windows CE Windows Server 2003 32 bit & 64 bit Editions Windows XP 32 bit & 64 bit Editions PCI 3.0 : Peripheral Component Interface
Approvals 	Other Approvals Microsoft Approvals	EMC: CE FCC Compliant Microsoft Certified Gold Partner Windows Server 2008 32 bit & 64 bit editions Windows Vista 32 bit & 64 bit editions Windows Server 2003 32 bit & 64 bit editions Windows XP 32 bit & 64 bit editions
General	PCB Layers Power Consumption Weight Size	4 200mA @ 5V, 7mA @ 12V 0.076 Kg 0x0x0 mm
Box Content	Packaging Card	Installation CD including manual, Microsoft signed drivers & utilities uPCI 2xRS232 230K / No Cable; Integrated Connector
Product Support 	Warranty Support	Lifetime (online registration required) Lifetime Web, Email and Phone Support from fully qualified, friendly staff who work in and alongside the Product Development Team
Additional 	OEM option Made In Customisable	Available for bulk buy OEM Manufactured in the UK by Brainboxes Winner 2005 European Electronics Industry Awards "Manufacturer of the Year" Brainboxes operate a "Perfect Fit Custom Design" policy for volume users. More Info: sales@brainboxes.com