

453-912 → 453-961


# WIDE TEMPERATURE RANGE POCKET SIZED THERMOMETERS MODELS 720C AND 720F

- **1/4 PERCENT ACCURACY**

- 160 TO 999°F
- 160 TO 850°C

- **LONG LIFE BATTERY OPERATION**

- **LIQUID CRYSTAL DIGITAL DISPLAY**

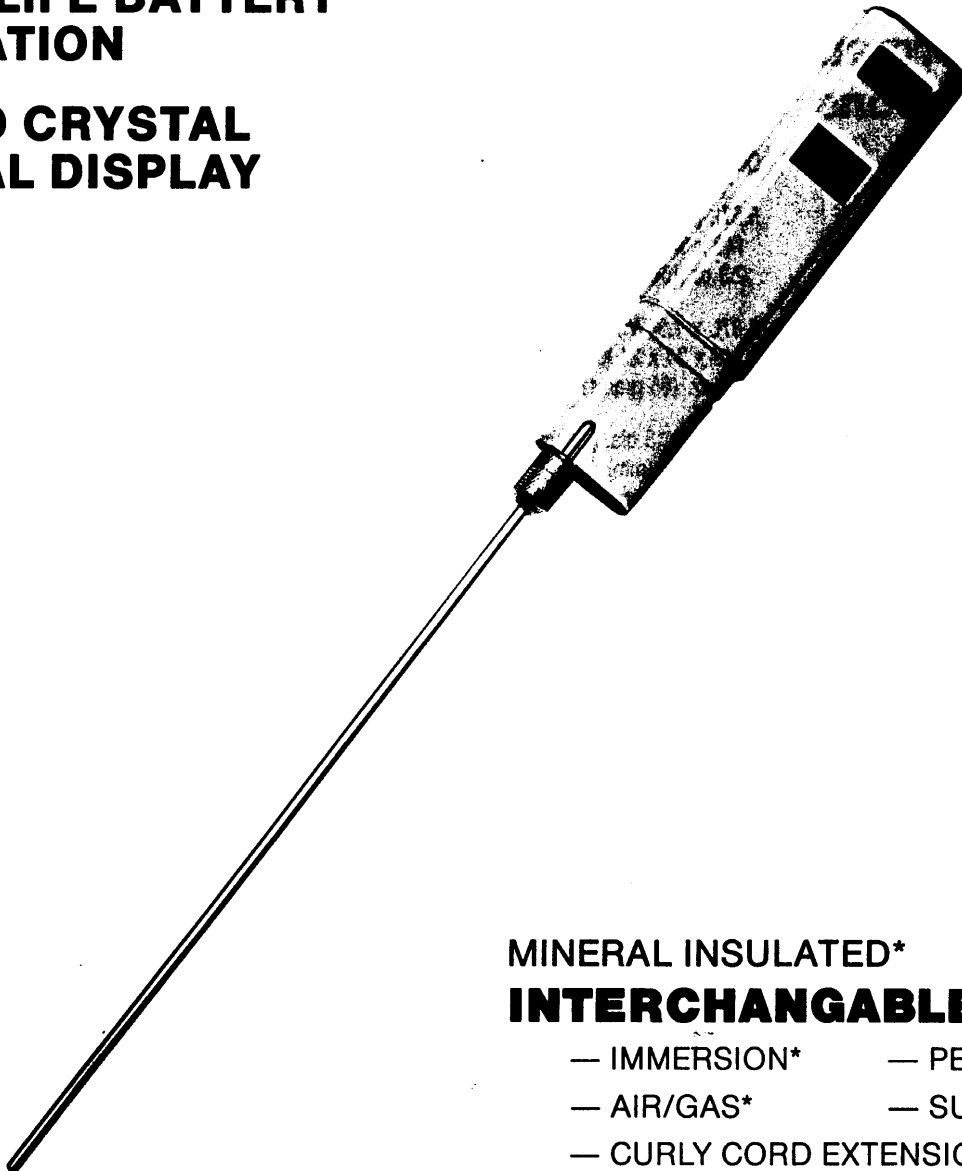

**MINERAL INSULATED\***

## **INTERCHANGABLE PROBES**

- IMMERSION\*
- AIR/GAS\*
- CURLY CORD EXTENSION/ADAPTER FOR SPECIAL APPLICATIONS
- PENETRATION\*
- SURFACE

\*MODELS 720-01, 720-02, 720-03

## Description


Factory calibrated for either Celcius or Fahrenheit, model 720 can be supplied with four interchangeable type K thermocouples. These mineral insulated, high quality stainless steel probes are intended for immersion (720-01\*), penetration (720-02\*), air/gas (720-03\*), or surface (720-04) temperature measurement applications. Optional 6 foot curly extension cord (720-31) is available to adapt other K type thermocouple probes with standard mini connectors. When ordering, specify either model 720F or 720C. Includes 4 type LR-44 batteries. Average battery life, 250 hours. Probes sold separately or as part of a complete set. Sets contain one each model 720F or 720C meter, probes 720-01/02/03/04, and a five compartment padded vinyl carrying case 720-99.

## Ordering Information and Specifications


Catalog	Application	Dimensions/Weight
720F	Digital pocket thermometer, °F	5.87L x 1.34W x .83D (inches) 149 x 34 x 21 (mm) 2.3 oz. (66 grams)
720C	Digital pocket thermometer, °C	5.87L x 1.34W x .83D (inches) 149 x 34 x 21 (mm) 2.3 oz. (66 grams)
720-01*	Immersion/general purpose probe	7.50L x 0.13 dia. (inches) 190 x 3.3 (mm) 0.6 oz. (16 grams)
720-02*	Penetration probe (semi-solids)	6.50L x 0.13 dia. (inches) 165 x 3.3 (mm) 0.5 oz. (14 grams)
720-03*	Air/Gas probe	7.50L x 0.19 dia. (inches) 190 x 4.8 (mm) 0.6 oz. (16 grams)
720-04	Surface contact probe	7.50L x 0.25 dia. (inches) 190 x 6.4 (mm) 0.6 oz. (16 grams)
720-31	Type K curl-cord extension/adaptor	6 feet extended 2 meters 2.8 oz. (80 grams)
720-99	Vinyl carrying case	9L x 4.5W (inches, approx.) 230 x 115 (mm) 2.1 oz. (60 grams)

720F-K Set incl °F meter, 4 SS probes, in padded vinyl carrying case with belt loop.  
720C-K Set incl °C meter, 4 SS probes, in padded vinyl carrying case with belt loop.

\*mineral insulated.

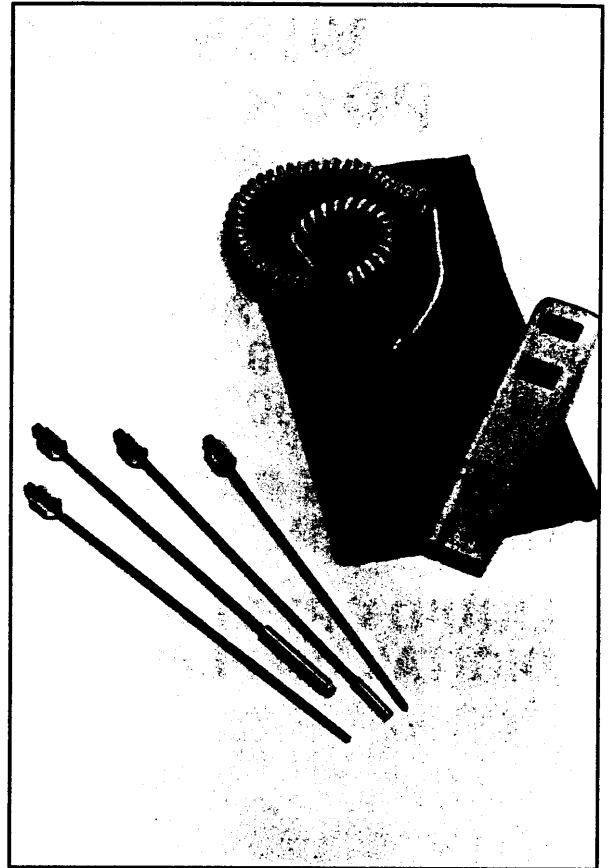

**COMPLETE SET SHOWN WITH OPTIONAL CURLY CORD/EXTENSION (720-31).**

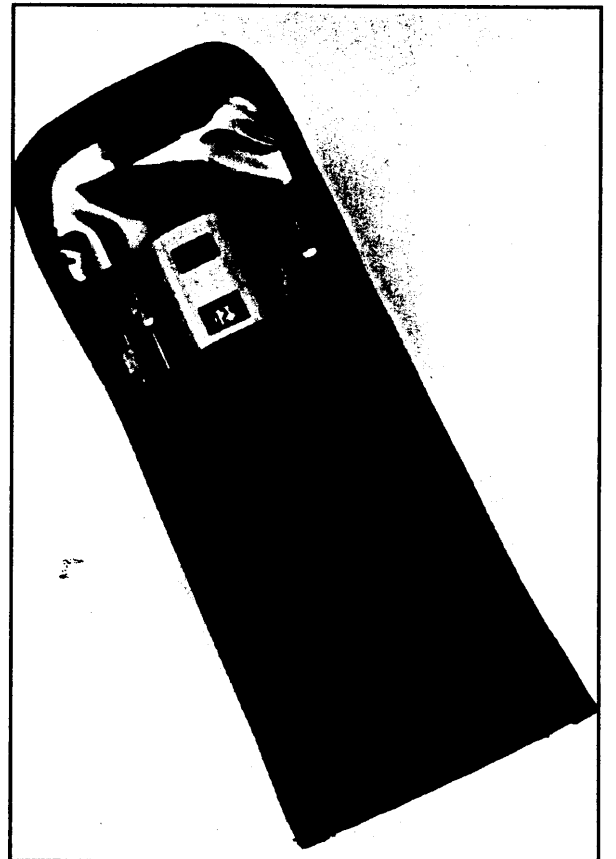

**MODEL 720F/C-K COMPLETE SET IN PADDED CARRYING CASE.**