

### Magnetic Cylinder Stainless Steel Series CG5

- SUS304 - stainless steel.
- Special scrapers provide optimum piston rod sealing.
- Seals either NBR or FKM.
- FDA approved grease suitable for food processing applications.
- CG5 can be disassembled, therefore maintenance-friendly.




Port Sizes: <u>Bore</u>	
6mm	M3
10mm	M5
15mm	M5
20mm	M5
25mm	G1/8
32mm	G1/8

• Signal Generators available on request.

**SERIES CG5 - Stainless Steel Magnetic Cylinder** 3360 For Reed Switches see below

BORE (mm)	STROKE (other lengths available)						
		25	50	75	100	125	150
20	PART NUMBER	CDG5BN20SR-25	CDG5BN20SR-50	CDG5BN20SR-75	CDG5BN20SR-100	CDG5BN20SR-125	CDG5BN20SR-150
25	PART NUMBER	CDG5BN25SR-25	CDG5BN25SR-50	CDG5BN25SR-75	CDG5BN25SR-100	CDG5BN25SR-125	CDG5BN25SR-150
32	PART NUMBER	CDG5BN32SR-25	CDG5BN32SR-50	CDG5BN32SR-75	CDG5BN32SR-100	CDG5BN32SR-125	CDG5BN32SR-150
40	PART NUMBER	CDG5BN40SR-25	CDG5BN40SR-50	CDG5BN40SR-75	CDG5BN40SR-100	CDG5BN40SR-125	CDG5BN40SR-150
50	PART NUMBER	CDG5BN50SR-25	CDG5BN50SR-50	CDG5BN50SR-75	CDG5BN50SR-100	CDG5BN50SR-125	CDG5BN50SR-150
63	PART NUMBER	CDG5BN63SR-25	CDG5BN63SR-50	CDG5BN63SR-75	CDG5BN63SR-100	CDG5BN63SR-125	CDG5BN63SR-150
80	PART NUMBER	CDG5BN80SR-25	CDG5BN80SR-50	CDG5BN80SR-75	CDG5BN80SR-100	CDG5BN80SR-125	CDG5BN80SR-150
100	PART NUMBER	CDG5BN100SR-25	CDG5BN100SR-50	CDG5BN100SR-75	CDG5BN100SR-100	CDG5BN100SR-125	CDG5BN100SR-150

OPTIONS: Without Magnet, FKM Seals, Long Stroke Version on request

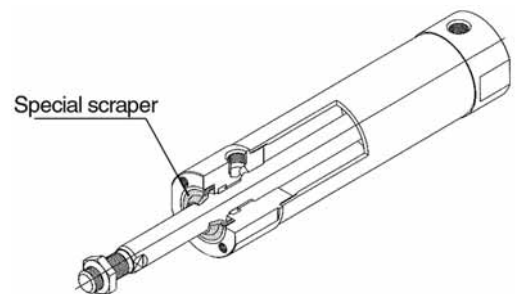

**SERIES CG5 - Cylinder Mounting** 3360

	BORE SIZE (mm)							
	20	25	32	40	50	63	80	100
Foot Type	CG-L020SUS	CG-L025SUS	CG-L032SUS	CG-L040SUS	CG-L050SUS	CG-L063SUS	CG-L080SUS	CG-L100SUS
Flange Type	CG-F020SUS	CG-F025SUS	CG-F032SUS	CG-F040SUS	CG-F050SUS	CG-F063SUS	CG-F080SUS	CG-F100SUS

**SERIES CG5 - Mounting Band for Auto Switch** 3360

PART NUMBER	BORE SIZE (mm)							
	20	25	32	40	50	63	80	100
	NBA-088S	NBA-106S	BGS1-032S	BAF-04S	BAF-05S	BAF-06S	BAF-08S	BAF-10S

Reed Switch

PART NUMBER	
D-G5BAL	