


Magnetic Sounders **MZT Series**

MZT-03A BLK (EIAJ MS-RT2-V15-27)

- Compact
Small and slim size of 10mm(W) × 12mm (L) × 2mm(H)
- The unique structure and its housing allow for reflow process
- Tape and reel packaging for auto mounting



Frequency response

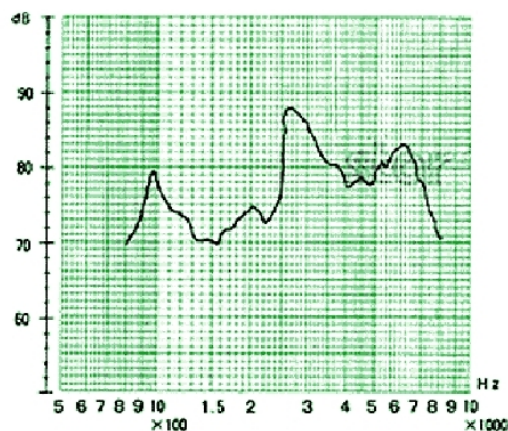


MZT-03A BLK

Applied voltage:
3.6V, square wave,
1/2 duty
distance for
measurement: 10cm

Specifications

Type	MZT-03A BLK
Rated Voltage (V)	3.6
Mean Current Consumption (mA)	MAX70 (TYP60)
Coil Resistance (Ω)	24 ± 3
*Sound Output at 10cm (dB)	MIN83 (TYP87)
Rated Frequency (Hz)	2670
Operating Voltage (V)	MAX 4.2
Operating Temperature (°C)	-20 to +60
Storage Temperature (°C)	-40 to +85
Weight (g)	0.5
*Value applying rated voltage (2670Hz, 1/2duty, square wave)	

Dimensions

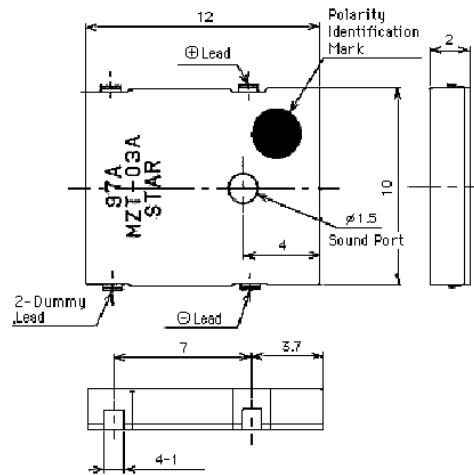

unit: mm
housing material: LCP