


**600 mm LED Light Bar (White SMD multi-LED)**

**LB6002012CW**

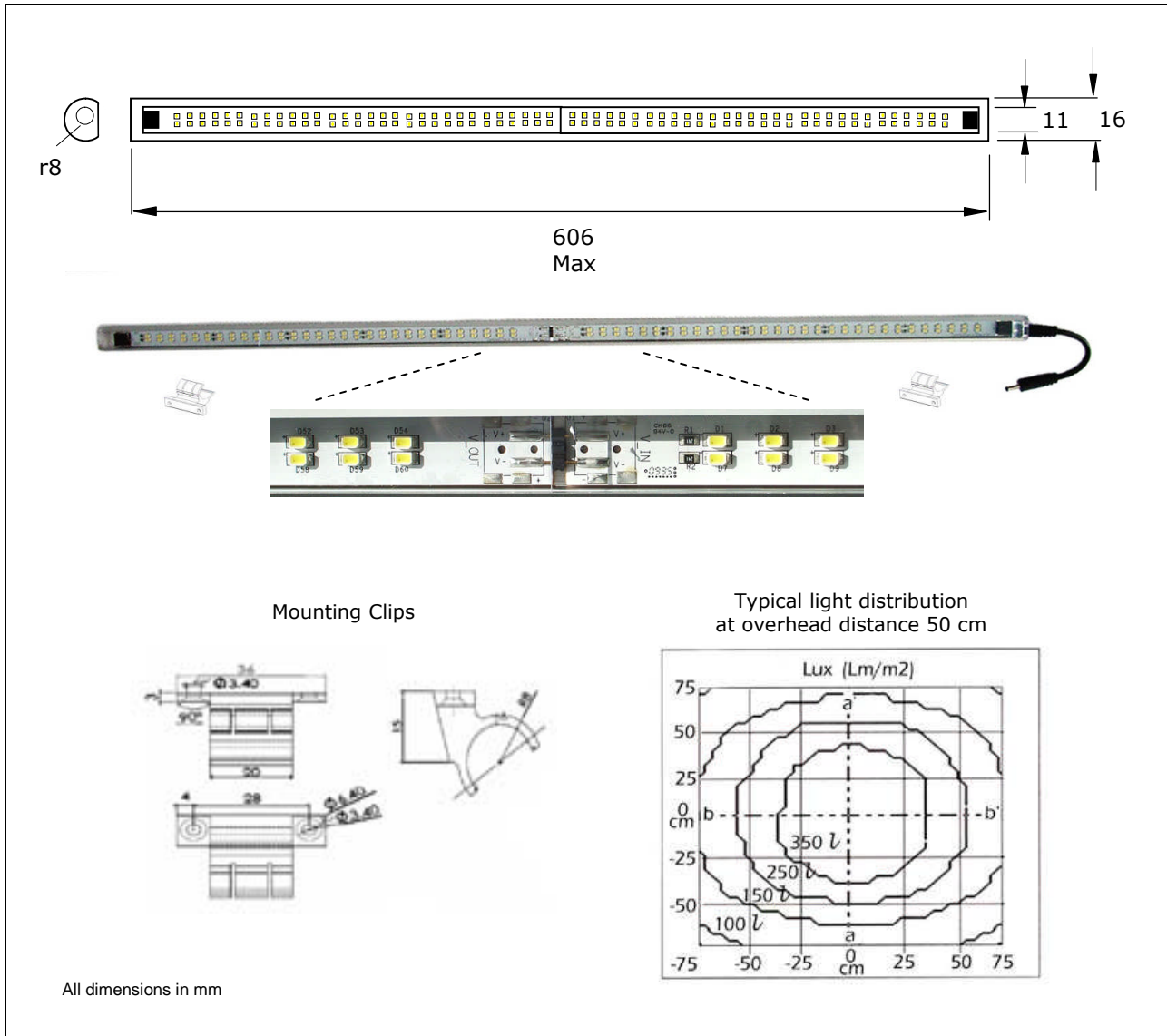

All dimensions in mm

**Product Characteristics**


Operating Voltage	24VDC
Power Consumption	12W
Number of LED rows	Two
Number of LEDs	120
Overall Length	606 mm Maximum.
Nominal Light output	440 Lumens
Colour Temperature	5500°K (Cool White)
Viewing Angle	100°
Power Connector	ø3.5mm x 1.3mm
Life Duration	20,000 hours.
Ingress Protection Rating	IP40
Construction	Rigid circuit board (2-off) within matt aluminium casing, clear acrylic lens cover and end caps.

**Notes.**

- 1) Light Bar supplied with two mounting clips and one daisy-chain connector.
- 2) RoHS compliant.

**600 mm LED Light Bar (White SMD multi-LED)**

**LB6002012NW**

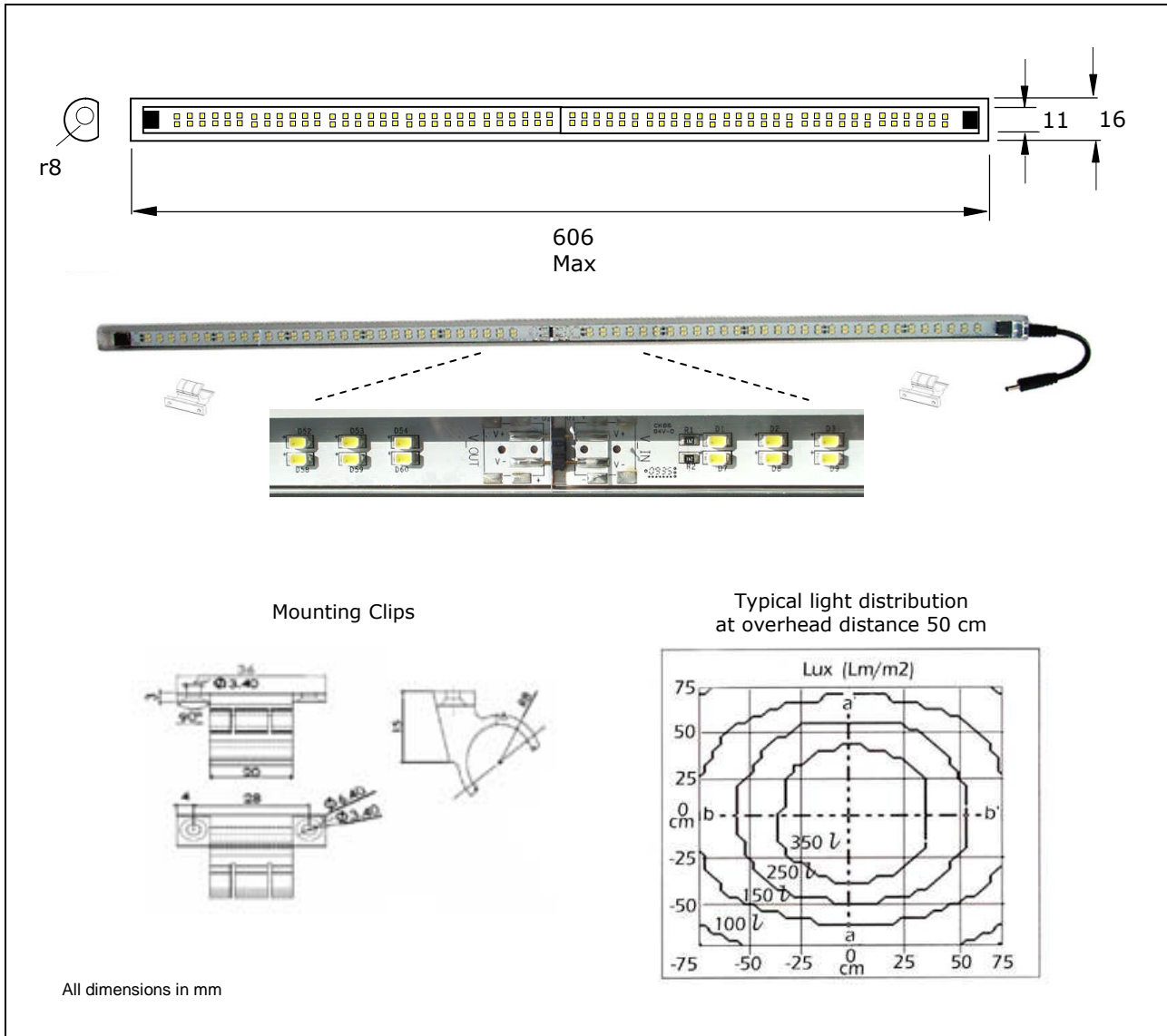

All dimensions in mm

**Product Characteristics**

Operating Voltage	24VDC
Power Consumption	12W
Number of LED rows	Two
Number of LEDs	120
Overall Length	606 mm Maximum.
Nominal Light output	400 Lumens
Colour Temperature	3500°K (Neutral White)
Viewing Angle	100°
Power Connector	ø3.5mm x 1.3mm
Life Duration	20,000 hours.
Ingress Protection Rating	IP40
Construction	Rigid circuit board (2-off) within matt aluminium casing, clear acrylic lens cover and end caps.

**Notes.**

- 1) Light Bar supplied with two mounting clips and one daisy-chain connector.
- 2) RoHS compliant.