







PRODUCT DATASHEET

50VA CHASSIS MOUNTED TRANSFORMER

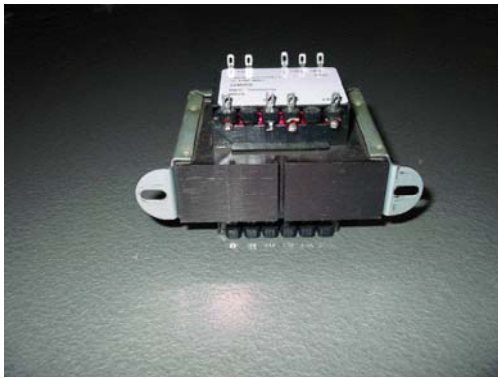

-  Designed, Manufactured and tested in accordance with **BS3535, EN60742* , EN61558* , BS415.**
-  Dual Primaries. For use with 110, 220, 240 input
-  4000V isolation Primary - Secondary
-  Comprehensive choice of Secondary Voltages.
-  Fully shrouded double section construction.

Weight	1.0	Kg
Typical Regulation	10	%
Frequency	50/60	Hz
Max Ambient	25	°C
Bobbin Material	UL94-HB Class "B" 130°C	

*requires additional over-current /over-temperature protection.

Please see sheet 2 for part numbers.

Part Numbers

Part No	Primary	Secondary	Recommended Secondary Fuse
D3657	0-110 0-110-130V	4.5+4.5V	5.0AT
D3658	0-110 0-110-130V	6+6V	4.0AT
D3659	0-110 0-110-130V	9+9V	2.5AT
D3660	0-110 0-110-130V	10V	5.0AT
D3661	0-110 0-110-130V	12+12V	2.0AT
D3662	0-110 0-110-130V	15+15V	1.60AT
D3663	0-110 0-110-130V	18+18V	1.5AT
D3664	0-110 0-110-130V	20+20V	1.25AT
D3665	0-110 0-110-130V	24+24V	1.00AT

Please see sheets 3 and 4 for dimensions, pin outs and connection information.

DAGNALL ELECTRONICS LIMITED

Shuttleworth Road, Elms Industrial Estate, Bedford. MK41 0EP UK

TEL +44(0)1234 330077 FAX +44(0)1234 330088




E-mail sales@dagnall-electronics.com

Issue 1. 14/05/03

3 of 4

PRODUCT DATASHEET

50VA CHASSIS MOUNTED TRANSFORMER

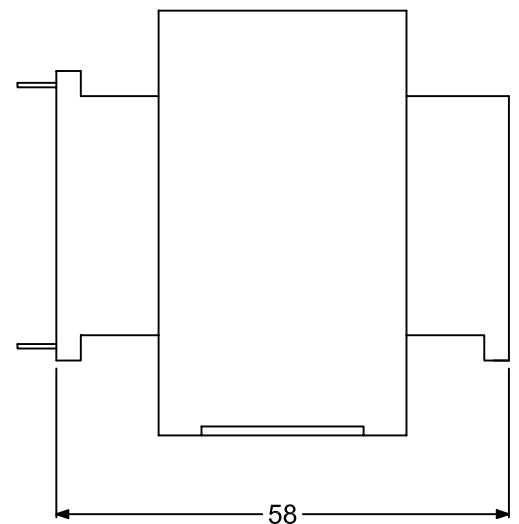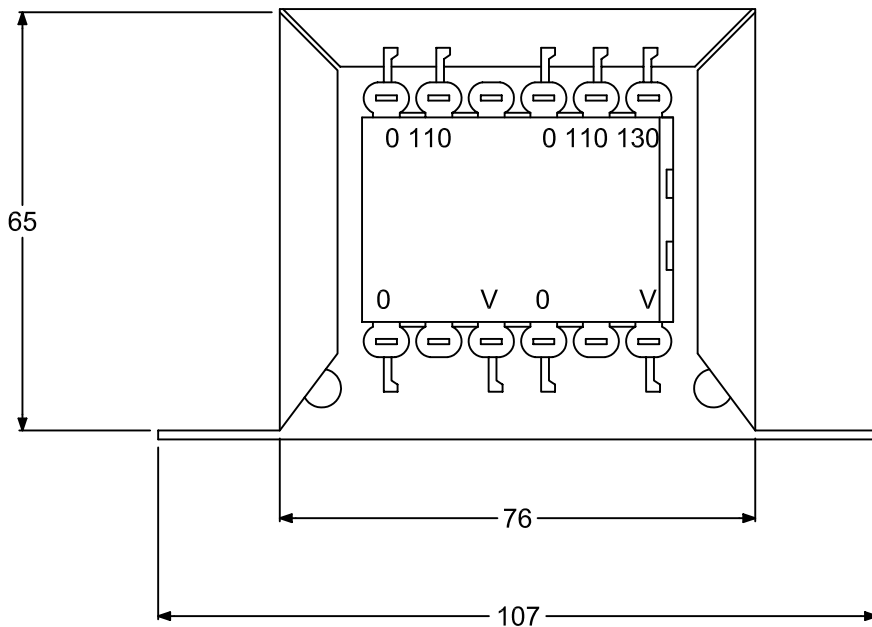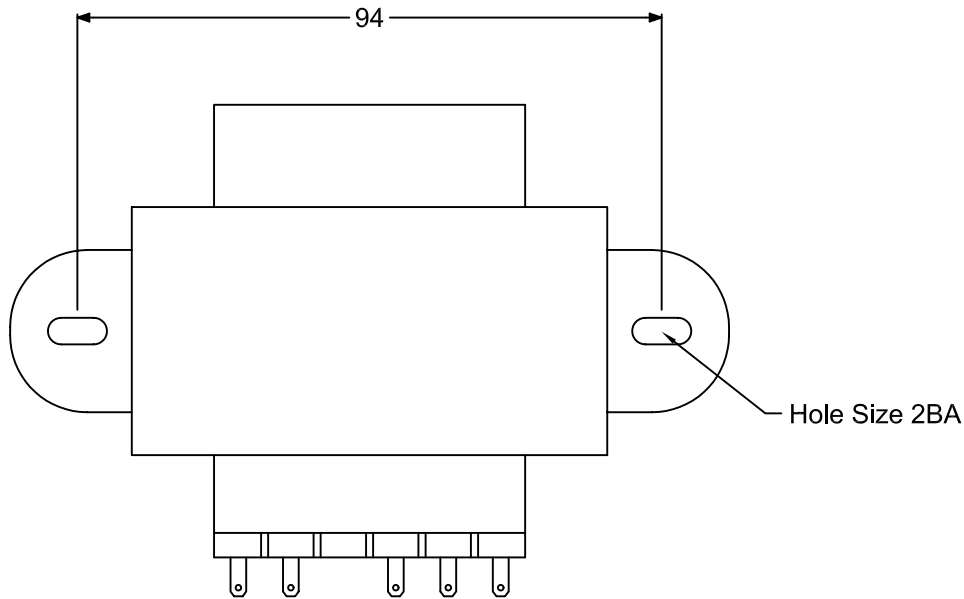

DAGNALL ELECTRONICS LIMITED

Shuttleworth Road, Elms Industrial Estate, Bedford. MK41 0EP UK

TEL +44(0)1234 330077 FAX +44(0)1234 330088

E-mail sales@dagnall-electronics.com

Issue 1. 14/05/03

4 of 4

PRODUCT DATASHEET

50VA CHASSIS MOUNTED TRANSFORMER

Connection Diagrams for D3657

