
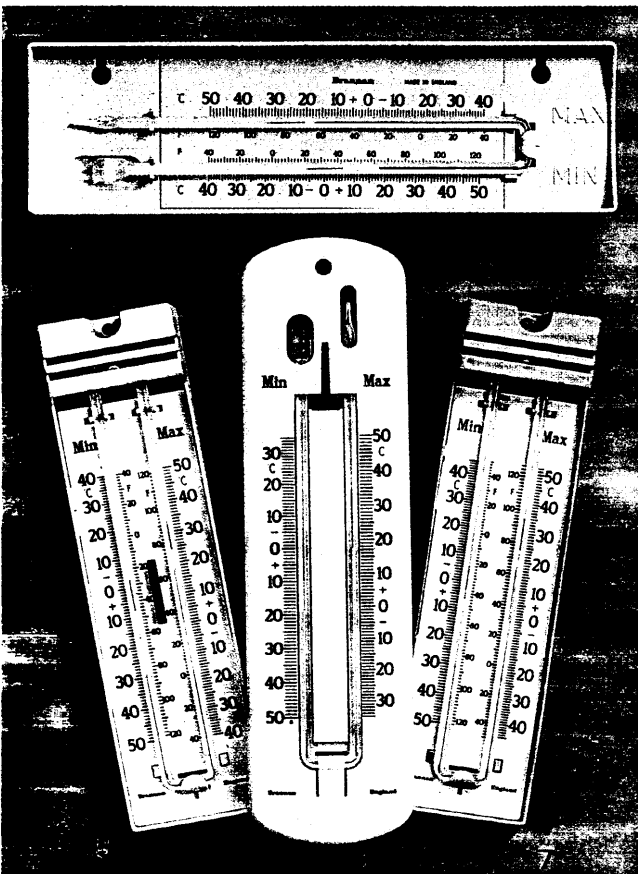


Maximum-Minimum

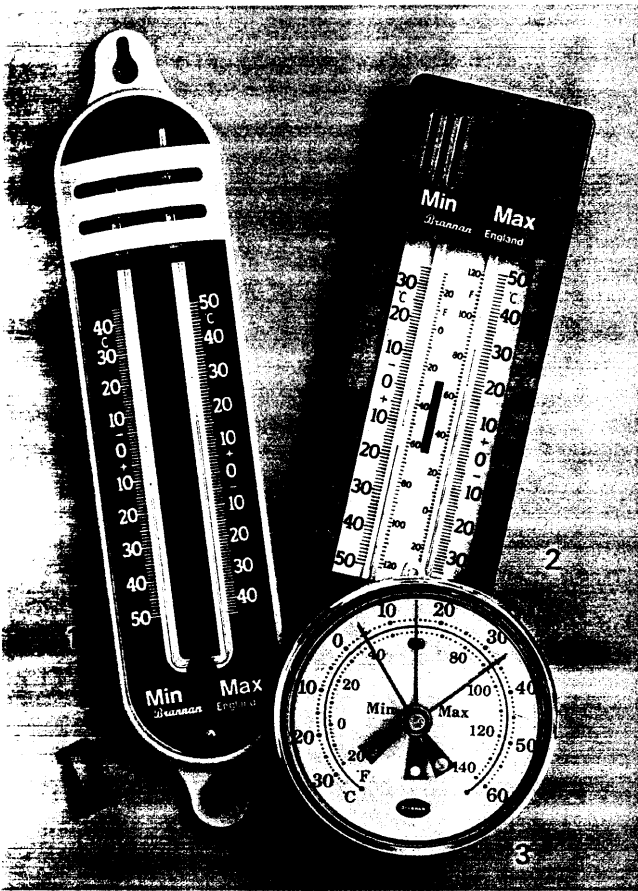

Maximum-Minimum Recording Thermometers. A wide choice of designs and ranges for all countries and markets. Packed singly.

1. Heavy-Duty Magnet Max-Min. Moulded in robust grey plastic. Separate resetting magnet.

-30/50C & -20/120F	Product No. 12/039/3
-30/50C	12/039/2
-45/50C & -40/120F	12/939/3

2. Press-Button Max-Min with enclosed case design in green. No separate magnet needed.

-30/50C & -20/120F	Product No. 12/642/3
-30/50C	12/642/2
-45/50C & -40/120F	12/952/3

3. Dial Max-Min Thermometer. Robust hanging 100mm metal case with chrome bezel. Black needle moves blue and red pointers into position. Use central knobs to reset.

-30/60C & -20/140F	Product No. 12/643/3
--------------------	----------------------

4. Horizontal Max-Min. Cream body which simply tilts vertically to reset the indices.

-20/50C & -20/120F	Product No. 12/001/3
-20/50C	12/001/2
-30/120F & -35/50C (°F dominant)	12/002/3
-45/50C & -40/120F	12/007/3

5. Quick-Set Press-Button Max-Min. Moulded in cream case with white scale. No separate magnet needed.

-30/50C & -20/120F	Product No. 12/038/3
-30/50C	12/038/2
-45/50C & -40/120F	12/838/3
-45/50C	12/838/2

6. Slimline Magnet Max-Min. Lightweight white body with separate slot-in resetting magnet.

-30/50C & -20/120F	Product No. 12/644/3
-30/50C	12/644/2
-45/50C	12/744/2

7. Hi-Lo Magnet Max-Min. Moulded in pale grey with white scale. Separate resetting magnet.

-30/50C & -20/120F	Product No. 12/641/3
-30/50C	12/641/2
-45/50C & -40/120F	12/841/3
-45/50C	12/841/2

Not illustrated. Stainless Steel Cased Max-Min. Separate resetting magnet.

-10/110C	Product No. 27/040/2
-10/150C	27/140/2
-10/200C	27/240/2