

**EPERMINGTON**  
**DROPPING**  
**2170**  
**3590**  
**2180**  
**P29**

## 2170: Funnels, dropping

Complies with BS 2021 and ISO 4800

Cylindrical shape with interchangeable ground glass stopcock and stopper.

| Catalogue number | Capacity ml | Stopcock bore mm | Stopper size | Approx. overall height mm | Stem OD mm |
|------------------|-------------|------------------|--------------|---------------------------|------------|
| 2170/02          | 25          | 2.5              | 14/23        | 245                       | 10         |
| 2170/04          | 50          | 2.5              | 19/26        | 275                       | 10         |
| 2170/06          | 100         | 2.5              | 19/26        | 295                       | 10         |
| 2170/08          | 250         | 2.5              | 24/29        | 365                       | 10         |
| 2170/10          | 500         | 4.0              | 24/29        | 415                       | 13         |
| 2170/12          | 1000        | 4.0              | 29/32        | 465                       | 13         |

\* Supplementary to BS and ISO ranges.



2170


## 3590: Funnels, dropping, graduated

Complies with BS 2021 and ISO 4800

Cylindrical shape with interchangeable ground glass stopcock and stopper. For convenience, this funnel is graduated to show approximate capacity.

| Catalogue number | Capacity ml | Grad intervals ml | Lowest grad mark ml | Tolerance on capacity ± ml | Stopcock bore mm | Stopper size |
|------------------|-------------|-------------------|---------------------|----------------------------|------------------|--------------|
| 3590/02          | 100         | 2                 | 10                  | 2                          | 2.5              | 19/26        |
| 3590/04          | 250         | 5                 | 25                  | 5                          | 2.5              | 24/29        |
| 3590/06          | 500         | 10                | 50                  | 10                         | 4.0              | 24/29        |
| 3590/08          | 1000        | 20                | 100                 | 20                         | 4.0              | 29/32        |

Stem O/D 100 & 250ml = 10mm  
 500 & 1000ml = 13mm

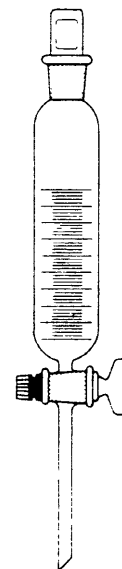


3590

## 2180: Funnels, separating

Pear shaped with interchangeable ground glass stopcock and stopper.

| Catalogue number | Capacity ml | Stopcock bore mm | Stopper size | Stem OD mm |
|------------------|-------------|------------------|--------------|------------|
| 2180/02M         | 50          | 2.5              | 19/26        | 10         |
| 2180/04M         | 100         | 2.5              | 19/26        | 10         |
| 2180/06M         | 250         | 4.0              | 24/29        | 13         |
| 2180/08M         | 500         | 4.0              | 24/29        | 13         |
| 2180/10M         | 1000        | 4.0              | 29/32        | 13         |
| 2180/12M         | 2000        | 4.0              | 34/35        | 13         |
| 2180/14M         | 5000        | 8.0              | 34/35        | 17         |

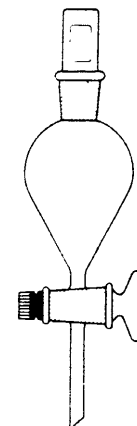

2180