


Part No.	(6)Length	Part No.	(6)Length
3182A-1	1M	3182A-5	5M
3182A-2	2M	3182A-10	10M
3182A-3	3M		

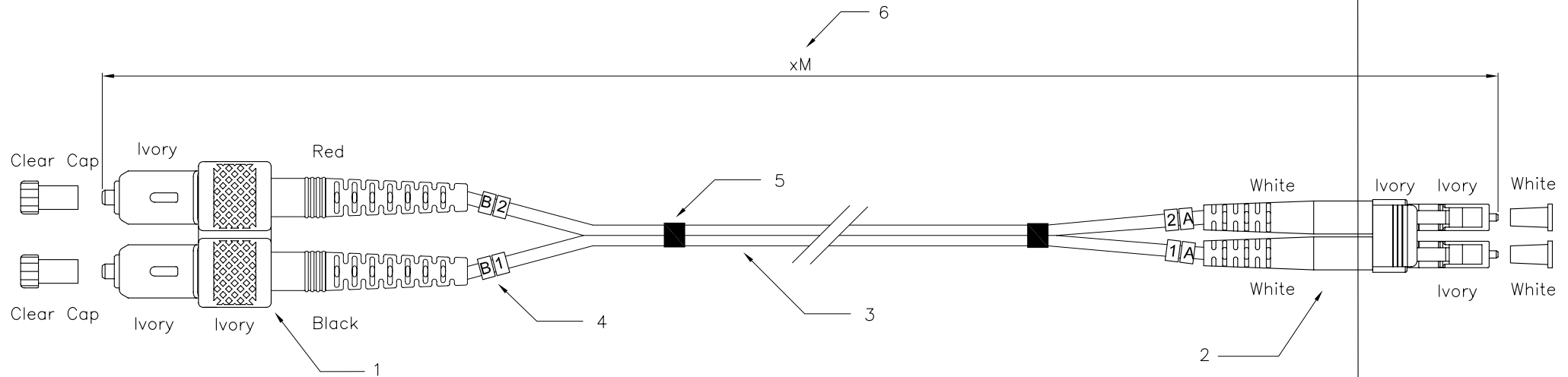

Specification:

1. Connector Type : II SC/PC Multimode
2. Connector Type : LC/PC Multimode
3. Cable Type :
 3-1 Zipcord cable, $\phi 3.0\text{mm}$, 50/125um Multimode
 3-2 Calbe Jacket : Orange color, LSZH material
4. Cable Marker
5. Shrink Tube
6. Length : xM

Performance:

- a. Insertion Loss : $< 0.5 \text{ dB}$
- b. Fiber Extention : $-0.05\mu\text{m} < H < +0.05\mu\text{m}$
- c. Ferrule End-face Radius : $7 < R < 25\text{mm}$
- d. Apex Offset : $< 50\mu\text{m}$
- e. Increase in insertion loss after 500 mating : 0.2 dB Max.
- f. Operation Temperature : $-20^\circ \text{ to } +70^\circ$
- g. Storage Temperature : $-40^\circ \text{ to } +80^\circ$

RoHS Compliant

	DSGN	CSQ	31.MAY.2007	ITEM NO: 3182A
	CHK	Maer	31.MAY.2007	
UNIT	M/M	APPR	Yty	SC to LC Duplex patch cord
SCALE	1/1			
DWG NO:	Videk Ltd			
3182A				