


Part No.	(5)Length	Part No.	(5)Length
3503-0.5	0.5M	3503-10	10M
3503-1	1M	3503-15	15M
3503-2	2M	3503-20	20M
3503-3	3M	3503-30	30M
3503-5	5M		

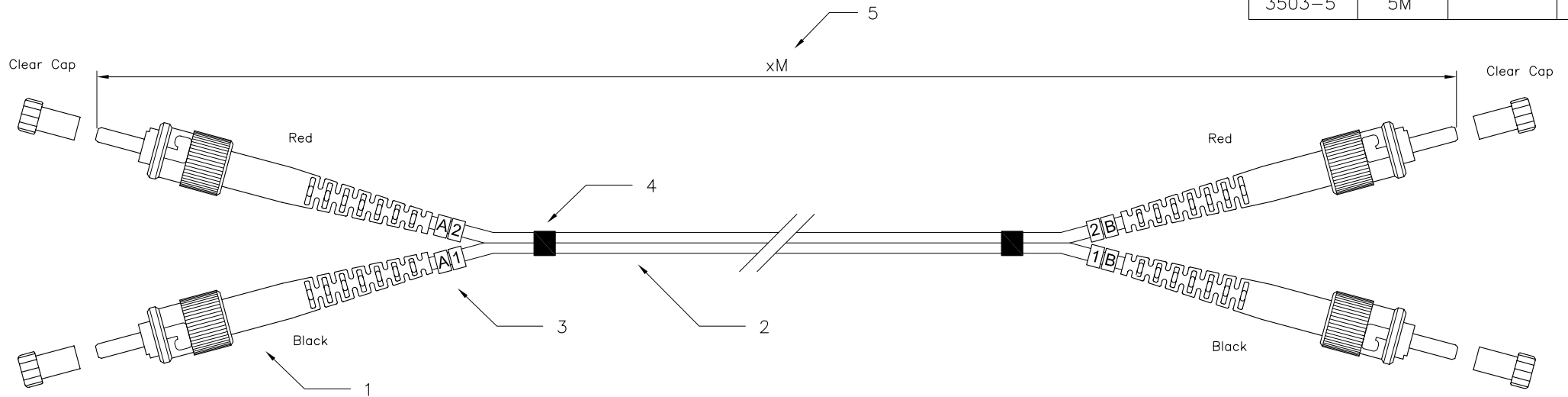

Specification:

1. Connector Type : ST/PC Multimode
2. Cable Type :
2-1 Zipcord cable, $\phi 3.0\text{mm}$, 62.5/125um Multimode
2-2 Calbe Jacket : Gray color, LSZH material
3. Cable Marker
4. Shrink Tube
5. Length : xM

Performance:

- a. Insertion Loss : $< 0.5 \text{ dB}$
- b. Fiber Extention : $-0.05\mu\text{m} < H < +0.05\mu\text{m}$
- c. Ferrule End-face Radius : $10 < R < 25\text{mm}$
- d. Apex Offset : $< 50\mu\text{m}$
- e. Increase in insertion loss after 500 mating : 0.2 dB Max.
- f. Operation Temperature : $-20^\circ \text{ to } +70^\circ$
- g. Storage Temperature : $-40^\circ \text{ to } +80^\circ$
- h. Humidity (non-condensing) 95%RH

RoHS Compliant

	DSGN	CSQ	30.MAY.2007	ITEM NO: 3503
	CHK	Maer	30.MAY.2007	
UNIT	M/M	APPR	Yty	30.MAY.2007
SCALE	1/1	ST to ST Duplex patch cord		
DWG NO: 3503	Videk Ltd			