


Products

- ▶ [Part Number Search](#)
- ▶ [Alphabetical Search](#)
- ▶ [Product Type Search](#)
- ▶ [Product Family Search](#)
- ▶ [Picture Search](#)
- ▶ [Industry Product Search](#)
- ▶ [Competitor Cross Reference](#)
- ▶ [Document Number Search](#)
- ▶ [Help/Glossary](#)

CPC (Circular Plastic) & Metal-Shell CPC Connectors


↳ CPC Connectors

206306-1 -- 1 of 1 products **Active**

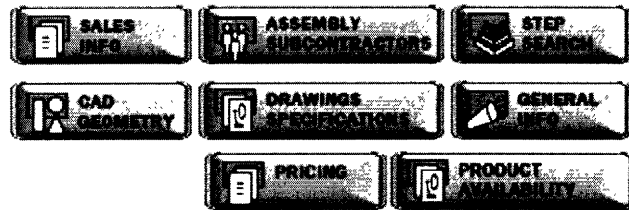

Please use the customer drawing for all design activity.

 - **Customer Drawing: 206306, Rev. K**
 Document Title: RECEPTACLE HOUSING,
 REVERSE SEX, SHELL SIZE 23, CPC



*Please use the customer drawing for all design activity.
 The photographs and/or line drawings below are
 representative images of a product for viewing purposes
 only.*

Product Photo

Keying Options

Searchable Features:

Other Properties:

Brand:	AMP	Wire Insulation Diameter (mm [in]):	2.54 [.100] Max.
Product Type:	Connector	Panel Attachment Method:	Square Flange
No. of Positions:	37	Housing Material:	Thermoplastic
Gender:	Receptacle	Housing Color:	Black
Pin/Socket:	Socket	Housing Material Flammability Rating:	UL 94V-0
Preloaded:	No	Keying:	A
Terminate To:	Wire		
Shell Size:	23		
Shell Type:	All Plastic		
Shell Thread Size:	1-3/8 - 18 UNEF-2A		
Numbering:	Reverse		
Product Series:	Series 1		
Mount Style:	Mounting Holes		
Sealed:	No		

VDE Tested: No
Standard or Reverse Gender: Reverse

Copyright and Privacy Statement Tyco Electronics Corporation
Visit Tyco International, Ltd

[\[back to top\]](#)
[Products](#) | [Industries](#) | [Commerce](#) | [About](#) | [Support](#) | [Home](#)