


Farnell InOne 257-006

ROUTING JIGS & ACCESSORIES

CRAFTSMAN ROUTER TABLE MK2

The Craftsman Router Table will suit craftsman and woodworking enthusiasts. It is packed with the necessary features to maximise the versatility of all popular portable routers.

- Large aluminium table with parallel ribs over full surface.
- Extension surface extends the width of table by over 400mm.
- Parallel adjustment system of backfence together with measurement strips.
- Fixing plate system beneath table. Plate must be ordered separately.
- High back fence.
- Sliding tenon push block for producing tenons.
- Optional leg stand with adjustable feet and enclosure option.

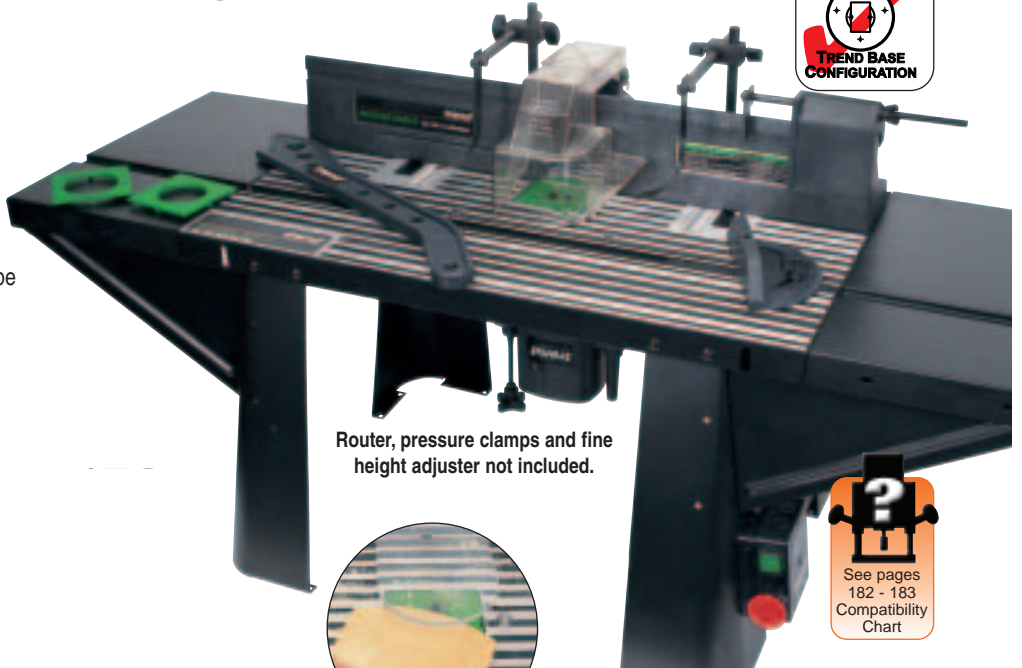

Router, pressure clamps and fine height adjuster not included.



Profiling with Optional Top Guard



Grooving

*See chart below right for choice.

Includes:

- 3 x Insert Rings
- 1 x No-volt Release Switch
- 1 x Tenon Block
- 1 x Mitre Fence
- 1 x Lead-on Pin
- 1 x Safety Guard
- 1 x Pushstick

Specification:

Rating _____ Craftsman
 Table top size (with extensions) 359 x 1030mm
 Table top size (without extensions) 359 x 605mm
 Bench height (without floor stand) 367mm
 Bench height (with floor stand) 1000mm
 Router cutter aperture 54mm
 Insert ring sizes 32mm, 48mm, 54mm
 Backfence height 100mm
 Dust spout aperture 57mmØ
 Edge planing up to 12.7mm
 Voltage 240v/115v

Optional Accessories:

Side Pressure Clamp
 CRT MK2 horizontal pressure guard for holding narrow work against the back fence. Can also be fitted to user-made tables.

CRT/11 _____

Spring Pressure Clamps
 The spring pressure clamps fit directly to the backfence. They maintain downward pressure when edge profiling or grooving.

CRT/10 (pair) _____

Vertical Routing Support
 This maintains side pressure and accommodates workpieces up to 50mm wide. Complete with instructions.

CRT/5 _____

Profiling Top Guard
 This is an important safety attachment when profiling with bearing guided cutters. It is clamped to table top and adjusted so that the cutter is guarded.

CRT/2 _____

3m Hose and Hose Adaptor
 If CRT table is to be used with T30 Extractor, use standard T30 hose fitted with CRT/3 adaptor (or purchase 58mm hose Ref. T30/22).

Adaptor CRT/3 _____
Hose CRT/4 _____
 39mm x 3 metre with a CRT/3 adaptor fitted

Hose T30/22 _____
 58mm x 1.5 metre for use with T30 Extractor

Floor Stand
 Steel floor stand with two shelves and four adjustable feet. Gives a working height of 1 metre.

 
CRT/FS _____

Enclosure Kit
 Four piece enclosure kit to bolt onto floor stand to create a storage cabinet.

CRT/EK _____

Fixing Plates*

A fixing plate to suit your model of router must be ordered separately.



To fit the following routers:

- CRT/FP/A** _____
- TREND T3, T5, T5 MK2, T9 AEG OF450S ●, 500S ●, OFE710 ● ATLAS COPCO OFS720 ●, OFSE850 ●, OFS50 ●, AXMINSTER AW635R ●, AW127R ● B&D SR100 ●, BD66 ●, DN67 ●, BD780(E), KW779, KW780(E) BOSCH POF52▲, 400▲, 500A▲, 600ACE▲, GOF1600A, 1700ACE CK LEKTO LRT700 ● CHAMPION CPR850 ● DEWALT DW613, 615, 620, 621, DW625EK, 629 DRAPER R850V ● EINHELL EOF850SP ● ELU MOF96(E) MK1 ● MOF96(E) MK2, OF97(E), MOF131, 177(E) JCB PR ● FELISATTI TP246(E) ●, R346EC FERM FBF-6E ●, FBF-8E ● FESTO OF900(E) ●, 1000(E) ●, 2000(E) ● HITACHI FM8 ●, ZK2008 ●, IM(V)(S) HOLZHER 2335 ●, 2355 ●, 2356 ●, KINZO 25C44 ●, 25C46 ● KANGO R8550S ● KRESS FM6955 ● LYNX RT-800-A ● MAFELL LO50E ●, 65E ● MAKITA RP0910, RP1110C ● METABO OF528 ●, OF1028 ●, OFE1229 ●, OF1612 ●, OFE1812 ● NUTOOL NPT850 ● PERFORMANCE POWER 1020W ●, PRO1250R ●, 1250RD, 2050R PERLES OF808(E) <1998 ●, OF808(E) >1999, OF2-808(E) ● PEUGEOT TDF800 ● POWER BASE 1020W ●, EXCEL1250W ●, POWER DEVIL PDW5027 ●, 5026 ●, 5038PR ● RYOBI R500 ●, R502 ● SPARKY X52E ● STAYER PR50 ● TRITON TRB001 ● VIRUTEX FR66F ●, FR77C ●, 78C ● WICKES 900W ● WADKIN R500 ●

CRT/FP/B _____
 BOSCH POF800ACE, GOF900A, 900ACE, GOF1300A RYOBI RE600N, R600N, RE601, R601

CRT/FP/C _____
 MAKITA 3600B ●, 3620, 3612(C), 3612BR

CRT/FP/D _____
 ATLAS COPCO OFSE2000 CASALS FT750, 1000E, 2000VCE DRAPER R1900V HITACHI M12SA, M12V(S), TR12 ● FAITHFUL FPPR2000E FREUD FT1000(E), FT2000(E) ● PEUGEOT DF55E, DEF570E RYOBI RE120, R150, R151, R152, RE155K SKIL 1835 ●, 1875U1 ●

- Re-drilling of router base required
- Re-drilling of insert plate required
- ▲ Packing piece required

Plate size 3 x 179 x 179mm