


Product Description

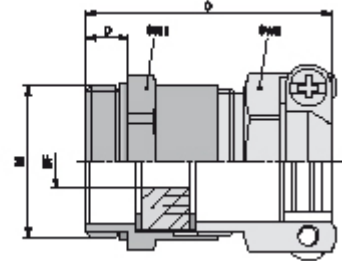

Application

Saddle clamp strain relief gland with additional seal, metric connection thread and according to EN 50262.

The design of the saddle clamp allows a wide clamping range with central cable clamping. Sealing is done with a single seal ring made of polychloroprene and the connection thread attached

O-ring made of Perbunan®.

Note

- Counter nut to be used SKINDICHT® SM-M
- For additional accessories see SKINDICHT® EV
- SKINDICHT® SKZ-M-XL is similar to the SKINDICHT® SKZ-M, but has an extended connection thread for thick walls

Special feature

Example - order identification:

SKZ-M 16 / 9

16 = Connection thread

9 = Function thread PG

**Technical Data****Caution**

Installation dimensions see T21

Material

Body: Nickel plated brass Incised sealing ring:

CR/NBR O-ring: NBR

Degree of protection

IP 55

Range of temperature

-20°C up to +80°C

Article List

Part number	Part designation / size	ØF mm	Max. fitting size for installation in mm	Function thread PG	Overall length C mm	Thread length D mm	SW1 / SW2 mm	Pieces / VPE
SKINDICHT® SKZ-M								
52106800	16 x 1,5	5 - 8	24	9	29	5	18 / 17	50
52106810	20 x 1,5	7 - 12	27	11	30	6	22 / 20	50
52106820	20 x 1,5	11 - 13	30	13.5	33,5	6	22 / 22	25
52106830	20 x 1,5	13 - 15	33	16	34,5	6	24 / 24	25
52106840	25 x 1,5	16 - 19,3	42	21	41	7	30 / 30	25
52106850	32 x 1,5	19 - 27	58	29	46	8	40 / 41	10
SKINDICHT® SKZ-M-XL								
52106805	16 x 1,5	5 - 8	24	9	34	10	18 / 17	50
52106815	20 x 1,5	7 - 12	27	11	34	10	22 / 20	50
52106825	20 x 1,5	11 - 13	30	13.5	37,5	10	22 / 22	25
52106835	20 x 1,5	13 - 15	33	16	38,5	10	24 / 24	25
52106845	25 x 1,5	16 - 19,3	42	21	45	11	30 / 30	25
52106855	32 x 1,5	19 - 27	58	29	51	13	40 / 41	10