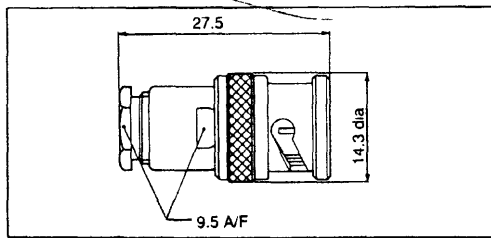
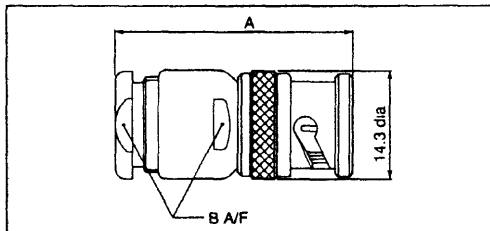



Straight plugs

Solder centre contact,
clamp outer

Impedance	Cable group ①	Part Number ②		Assy notes page:
50 ohm	010	B35 A01 •010 X99	Captive contact, pressure sleeve cable clamp	42 (a)
50 ohm	022	B35 A01 •022 X99	As above	42 (b)
50 ohm	024	B35 A01 •024 X99	As above	42 (b)
50 ohm	029	B35 A01 •029 X99	As above	42 (a)
50 ohm	030	B35 A01 •030 X99	As above	42 (a)
50 ohm	073	B35 A01 •073 X99	As above (for semi-rigid cable)	47 (a)
50 ohm	010	B35 A11 •010 X99	UG - style item, non-captive contact	43 (b)
75 ohm	025	B37 A48 •025 X99	As above	43 (b)

Solder centre contact,
clamp outer

Impedance	Cable group ①	Part Number ②	A	B		Assy notes page:
50 ohm	009	B35 A70 •009 X99	28.5	11.1	Captive contact, pressure sleeve cable clamp	42 (a)
50 ohm	010	B35 A06 •010 X99	28.5	11.1	UG-style item, non-captive contact, V groove gasket	43 (a)
50 ohm	010	B35 A07 •010 X99	28.5	11.1	Captive contact, V groove gasket, braid clamp	45 (b)
50 ohm	010	B35 A18 •010 X99	27.8	11.1	UG-style item, non-captive contact, V groove gasket	43 (a)
50 ohm	010	B35 A70 •010 X99	28.5	11.1	Captive contact, pressure sleeve cable clamp	42 (a)
50 ohm	022	B35 A70 •022 X99	28.5	11.1	As above	42 (b)
50 ohm	027	B35 A71 •027 X99	30.4	12.7	As above	42 (a)
50 ohm	060	B35 A70 •060 X99	28.5	11.1	As above	42 (a)
75 ohm	007	B37 A71 •007 X99	30.4	12.7	As above	42 (a)
75 ohm	012	B37 A70 •012 X99	28.5	11.1	As above	42 (a)
75 ohm	022	B37 A70 •022 X99	28.5	11.1	As above	42 (b)
75 ohm	025	B37 A07 •025 X99	28.5	11.1	Captive contact, V groove gasket, braid clamp	45 (b)
75 ohm	025	B37 A47 •025 X99	28.0	11.1	UG-style item, non-captive contact, V groove gasket	43 (b)
75 ohm	025	B37 A70 •025 X99	28.0	11.1	Captive contact, pressure sleeve cable clamp	42 (a)
75 ohm	027	B37 A71 •027 X99	30.4	12.7	As above	42 (a)
75 ohm	028	B37 A71 •028 X99	30.4	12.7	As above	42 (a)
75 ohm	030	B37 A70 •030 X99	28.5	11.1	As above	42 (a)
75 ohm	052	B37 A70 •052 X99	28.5	11.1	As above	42 (a)
75 ohm	062	B37 A70 •062 X99	28.5	11.1	As above	42 (a)
75 ohm	079	B37 A71 •079 X99	30.4	12.7	As above	42 (a)
75 ohm	117	B37 A70 •117 X99	28.5	11.1	As above	42 (a)
75 ohm	119	B37 A70 •119 X99	28.5	11.1	As above	42 (a)

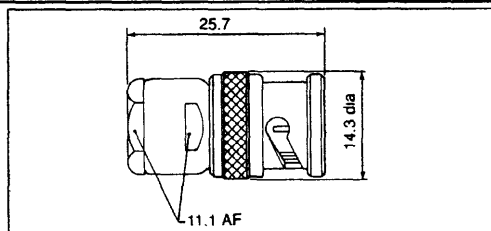Solder centre contact,
clamp outer

Impedance	Cable group ①	Part Number ②		Assy notes page:
75 ohm	025	B37 A53 •025 X99	3 part rapid assembly with tapered ferrule	49 (a)

① For cable group to cable type cross reference see fold out section of rear cover

② Replace the • in the part number with required plating code, see page 8 for details
Preferred items

Please contact the Sales Office for any uncatalogued requirements