
 **Combination pliers, 2628G** 

ISO: 5746

DIN: 5746

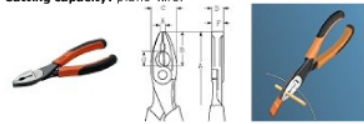
Finish: black oxidised, anti-corrosion treated.






Material: Chrome-Vanadium steel. With Ergo handles in two-material combination. Thermoplastic surface on tough polypropylene which gives a superior grip.

Shape: an "open" joint, in which the distance from the joint centre to the cutting edges is reduced, results in greater leverage and increased cutting capacity. Equipped with return spring with on/off function. Round shaped jaws give improved accessibility in confined spaces.

Application: the edges specially designed to cut harder material such as piano wire and spring steel wire. Gripping surfaces particularly suited for gripping round and flat material.

Cutting capacity: piano wire.



|  |  731416 |  | A mm | B mm | C mm | D mm | E mm | F mm | G mm |  |  |
|--|---|---|----------------|----------------|----------------|----------------|----------------|----------------|----------------|---|---|
| 2628 G-160 | 0042999 | 5 | 160 | 33 | 23 | 10.5 | 3.5 | 10.5 | 12 | 1.8 | 190 |
| 2628 G-180 | 0042678 | 5 | 180 | 36 | 25 | 11.0 | 4.0 | 11.0 | 14 | 2.0 | 240 |
| 2628 G-200 | 0103539 | 5 | 200 | 39 | 27 | 12.0 | 4.5 | 12.0 | 16 | 2.5 | 300 |
| 2628 G-160IP | 0055357 | 5 | 160 | 33 | 23 | 10.5 | 3.5 | 10.5 | 12 | 1.8 | 190 |