

Features and Specifications of hawkboard Platforms

Hardware

- OMAP L138 processor (ARM 300MHz +DSP 300MHz)
- 128MB DDR2 RAM
- 128MB NAND Flash
- Audio in / Audio out
- Composite Video In
- VGA
- Ethernet 10/100
- MMC / SD
- USB host
- USB OTG
- Serial
- JTAG
- 5V DC
- SATA

Expansion Connector Includes

- I2C
- SPI
- LCD signals
- VPIF
- MMC/ SD
- PWM
- eCAP
- UART
- GPIO
- PRU

Software

- Linux 2.6.2 X Kernel, Android OS

Dimension


- 90mm X 100mm

Development tools


- Toolchains for Kernel compilation.
- XDS 100 JTAG Emulator (optional)

Documentation

- User Guide
- Schematic Diagram

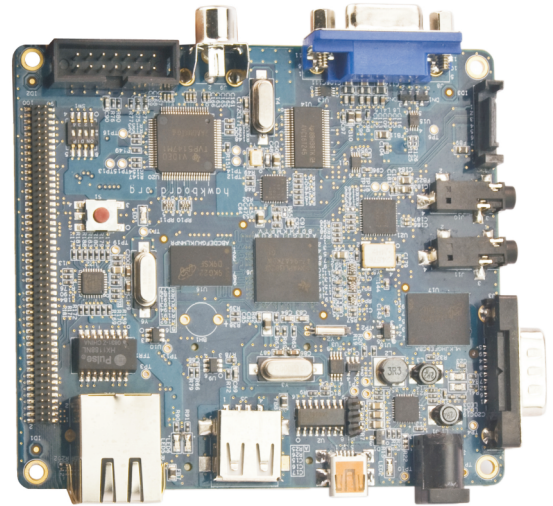

Contact Details:

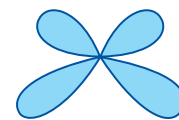

*Big Dreams
Better Tomorrow*

Innovate Software Solutions Pvt. Ltd
#333, 18th G Main Road
6th Block, Koramangala
Bangalore – 560095
Tel: +91-80-41105384
Fax: +91-80-25537138
Email: sales@innovatesolutions.net

www.innovatesolutions.net
www.hawkboard.org