

DESCRIPTION OF THE CABLE:

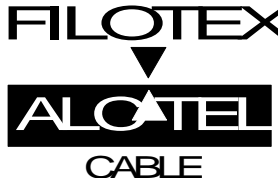
8 PAIRS CABLE

- 1: 7x0.20 mm tinned copper (0°22 AWG 24)
- 2: Halogen free insulation Ø 1.30 mm +/- 0.10 mm
- 3: Filler
- 4: Aluminium polyester tape
- 5: 0.15 mm tinned copper braid Kr > or = 55.30%
- 6: Halogen free outer jacket Ø 8.70 mm +/- 0.20 mm

CHARACTERISTICS:

Operating temperature: 85°c
Operating voltage 250 volts

Conformity to CEI 332.3

Ref. FILOTEX	Date	Edit.	PROJET	
296870	25/03/87	1		
PLAN DAO				

Caractéristiques données a titre indicatif