

## PST 1,3/ 3-5,0

Order No.: 1933192

The figure shows a 10-position version of the product

<http://eshop.phoenixcontact.net/phoenix/treeViewClick.do?UID=1933192>Header, Nominal current: 12 A, Nom. voltage: 250 V, Pitch: 5 mm,  
Number of positions: 3, Color: black, Assembly: Soldering

### Commercial data

|                          |                    |
|--------------------------|--------------------|
| EAN                      | 4017918918682      |
| Pack                     | 50 pcs.            |
| Customs tariff           | 85366990           |
| Weight/Piece             | 0.000631 KG        |
| Catalog page information | Page 480 (CC-2009) |

### Product notes

WEEE/RoHS-compliant since:  
01/01/2003

<http://www.download.phoenixcontact.com>  
Please note that the data given here has been taken from the online catalog. For comprehensive information and data, please refer to the user documentation. The General Terms and Conditions of Use apply to Internet downloads.

### Technical data

#### Dimensions / positions

|                     |        |
|---------------------|--------|
| Length              | 2.8 mm |
| Pitch               | 5 mm   |
| Dimension a         | 10 mm  |
| Number of positions | 3      |
| Pin dimensions      | 1,3 mm |

|                                    |                                 |
|------------------------------------|---------------------------------|
| Hole diameter                      | 1.5 mm                          |
| <b>Technical data</b>              |                                 |
| Insulating material group          | IIIa                            |
| Rated surge voltage (III/3)        | 4 kV                            |
| Rated surge voltage (III/2)        | 4 kV                            |
| Rated surge voltage (II/2)         | 4 kV                            |
| Rated voltage (III/2)              | 320 V                           |
| Rated voltage (II/2)               | 400 V                           |
| Connection in acc. with standard   | EN-VDE                          |
| Nominal current $I_N$              | 12 A (depends on the plug used) |
| Nominal voltage $U_N$              | 250 V                           |
| Maximum load current               | 12 A (depends on the plug used) |
| Insulating material                | PA                              |
| Inflammability class acc. to UL 94 | V0                              |

### Certificates / Approvals



Certification

CCA, CUL, GOST, SEV, UL

#### CUL


|                       |       |
|-----------------------|-------|
| Nominal voltage $U_N$ | 300 V |
| Nominal current $I_N$ | 10 A  |

#### UL



|                       |       |
|-----------------------|-------|
| Nominal voltage $U_N$ | 300 V |
| Nominal current $I_N$ | 10 A  |

**Diagrams/Drawings**


Drilling plan/solder pad geometry

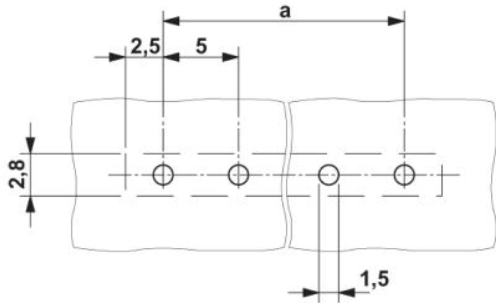

Diagram

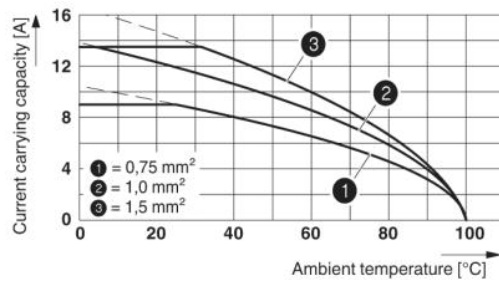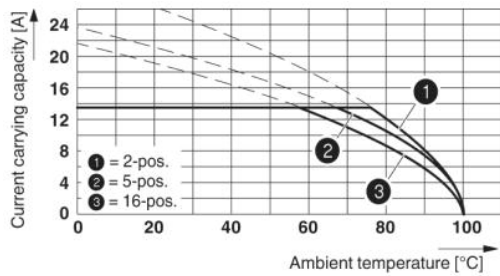

Dimensioned drawing

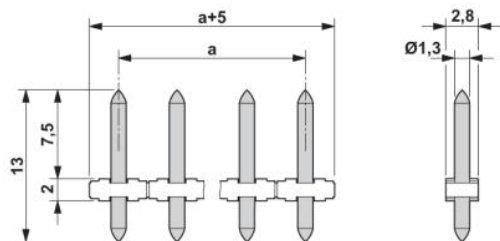

**Address**

PHOENIX CONTACT GmbH & Co. KG  
Flachsmarktstr. 8  
32825 Blomberg, Germany  
Phone +49 5235 3 00  
Fax +49 5235 3 41200  
<http://www.phoenixcontact.com>



© 2010 Phoenix Contact  
Technical modifications reserved;